

Curved track for plate chain






GCB880T For chain ranges 880 TAB and 881 TAB

- Used to support and guide CAP880T and CAP881T/SS plate chains
- Material
High density Black DESLIDUR

Info.

- Comprises 2 tracks (carry and return)

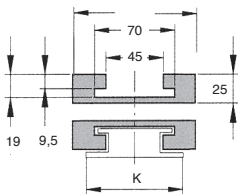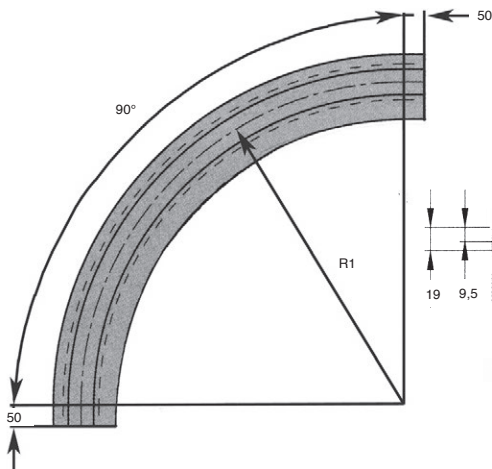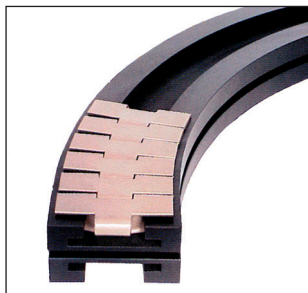

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	For chain	AG (mm)	R1 (mm)	K (mm)	Weight (kg)	Price each 1 to 4
GCB880T-82	CAP880T-82 CAP881T-82/SS	100	500	82,5	2,4	132,22 €
GCB880T-114	CAP880T-114 CAP881T-114/SS	130	610	114,3	4,4	256,76 €


Dimensions in mm

Altri prodotti...



PR125rehausse

Extension for articulated foot Ø123, Ø 123

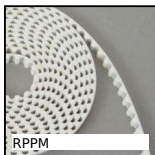

RPPM

Cinghia aperta al metro tipo RPP, RPP14 Poliuretano armatura in acci...




MDB_MTB

Ingranaggio conico in plastica stampata, 2:1



CHA60

Cerniera, Rettangolare forata o con fori svasati

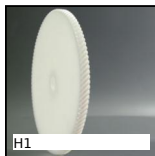

H1

Ingranaggio elicoidale ad assi incrociati a 90°, Plastica lavorata



CHNrb

Catena segnaletica rossa e bianca, Acciaio



BSM

Pressore a molla con esagono incassato, corpo in acciaio, spina in p...



SHW

Rondella semplice , Inox A2



CLSCLP

Forcella serie corta, Corta acciaio



PENV

Maniglia da incasso, Ad avvitare



PLS

Distanziatore cilindrico, Inox 303



BPMc

Pressore a molla con intaglio e puntale a sfera, Corpo inox 303 + ce...

Prodotti correlati



CAP880

Catena a tapparella, Stretta serie 880



CAP881

Catena a tapparella, Stretta serie 881



SDG

Supporto con tirante ad occhio, Plastica