

Curved track for plate chain






GCB880T For chain ranges 880 TAB and 881 TAB

- Used to support and guide CAP880T and CAP881T/SS plate chains

- Material
High density Black DESLIDUR

Info.

- Comprises 2 tracks (carry and return)

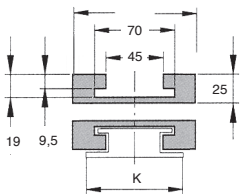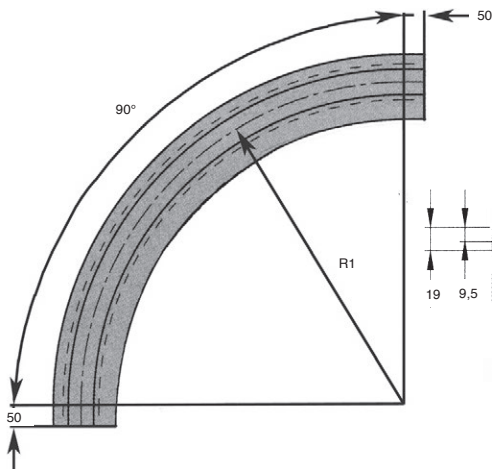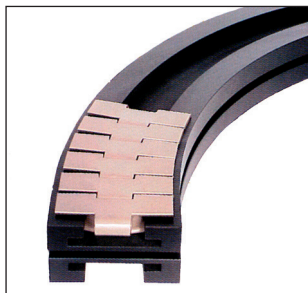

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request


Part number	For chain	AG (mm)	R1 (mm)	K (mm)	Weight (kg)	Price each 1 to 4
GCB880T-82	CAP880T-82 CAP881T-82/SS	100	500	82,5	2,4	132,22 €
GCB880T-114	CAP880T-114 CAP881T-114/SS	130	610	114,3	4,4	256,76 €

Dimensions in mm

Altri prodotti...



M2
Coppia ruota e vite senza fine, Acciaio non temprato

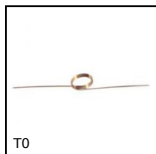

T0
Molla di torsione, Inox



ZG2
Ingranaggio dritto in plastica, Plastica lavorata (delrin)



PGR
Impugnatura cilindrica libera retraibile, Retraibile



NIN
Dado autofrenante, Acciaio




CHT
Motore AC asincrono trifase, 1.1 a 1.85kW



DILC
Indexing plunger with cam, with cam



CHAR
Cerniera a molla, avvitabile

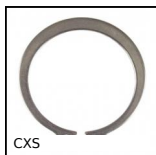

CXS
Anello di arresto esterno DIN471,



GCH
Guida lineare a sfere Eco, economica



PW_PWG2
Vite senza fine di precisione, Inox



MEB
Ingranaggio conico in plastica stampata, 1:1

Prodotti correlati



CAP880
Catena a tapparella, Stretta serie 880



CAP881
Catena a tapparella, Stretta serie 881



SDG
Supporto con tirante ad occhio, Plastica