

Curved track for plate chain





GCB880T For chain ranges 880 TAB and 881 TAB

- Used to support and guide CAP880T and CAP881T/SS plate chains
- Material
High density Black DESLIDUR

Info.

- Comprises 2 tracks (carry and return)

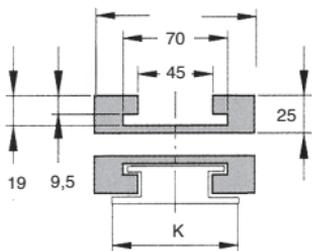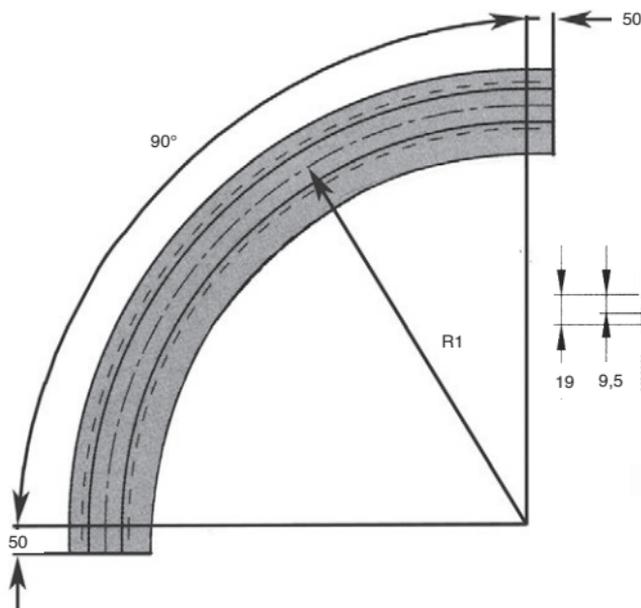

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	For chain	AG (mm)	R1 (mm)	K (mm)	Weight (kg)	Price each 1 to 4
GCB880T-82	CAP880T-82 CAP881T-82/SS	100	500	82,5	2,4	132,22 €
GCB880T-114	CAP880T-114 CAP881T-114/SS	130	610	114,3	4,4	256,76 €

Dimensions in mm

Altri prodotti...



VELM6

Supporto avvitabile per rotolo a strappo fermacavi, Poliammide



RBNpl

Ruota girevole a doppio bloccaggio, Acciaio - caucciù



G2

Ingranaggio dritto acciaio, Acciaio 20NCD2



PRF_CH

Catena porta cavo, Supplied in metre lengths




DOMI30

Kit di raccordo, Kit di raccordo XZ




LVT

Mini martinetto motorizzato 1A, 1 ampere

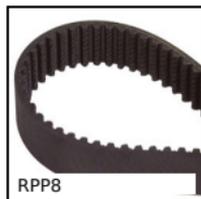

RPP8

Cinghia di trasmissione RPP, RPP8

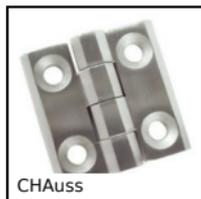

CHAuss

Cerniera ad avvitare, 270°



SRG

Chiusura a leva regolabile, Corsa da



AC156-157

Riscontro per chiusura a leva rigida ad



PTA150

Piede snodato con base stampata Ø150,



METEB

Barre autolubrificanti, Bronzo BP25

Prodotti correlati



CAP880

Catena a tapparella, Stretta serie 880



CAP881

Catena a tapparella, Stretta serie 881



SDG

Supporto con tirante ad occhio, Plastica