

Straight track for plate chain




GDR880T For chain ranges 880 TAB and 881 TAB

- Used to support and guide CAP880T and CAP881T/
SS plate chains

- Material:
Black DESLIDUR

Info.

- Comprises 2000mm tracks (carry and return)

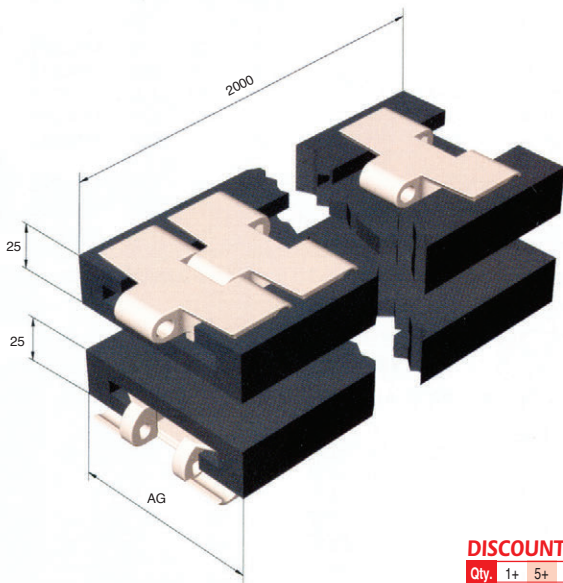

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	For chain	AG (mm)	Length (mm)	Weight (kg)	Price each 1 to 4
GDR880T-82	CAP880T-82 CAP881T-82/SS	100	2000	5,9	247,46 €
GDR880T-114	CAP880T-114 CAP881T-114/SS	130	2000	8,8	321,26 €

Dimensions in mm

Altri prodotti...



AC
Pastrina di riscontro,
15mm



DIV_SS
Pistoncino a molla,
Bloccabile - Inox



M0
Coppia ruota e vite
senza fine , Bronzo



CLG2
Ingranaggio dritto in
plastica stampata ,
Nylon stampato



DOMI80
Accessori di
collegamento, Piastra



ACLEFS
Elementi di
ancoraggio, Standard



AT5P_AT10P
Piastra di giunzione
per cinghia AT, AT10



HTD8M_20
Puleggia dentata di
trasmissione tipo
HTD, HTD8 Ghisa



ABL100005
Spazzola antistatica,
Standard



D-PAR_SS
Piedino antivibrante
parabolico, inox



HTD5M-BAR
Barra dentata per
cinghia RPP, HTD5



CQA20
Slitta di regolazione
miniatura, 20

Prodotti correlati




CAP880
Catena a tapparella,
Stretta serie 880



CAP881
Catena a tapparella,
Stretta serie 881



SDG
Supporto con tirante
ad occhio, Plastica

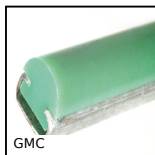

GMC
Guida prodotto
laterale tonda, Per
imbottigliamento e
imballaggio