

Straight track for plate chain




GDR880T For chain ranges 880 TAB and 881 TAB

- Used to support and guide CAP880T and CAP881T/
SS plate chains

- Material:
Black DESLIDUR

Info.

- Comprises 2000mm tracks (carry and return)

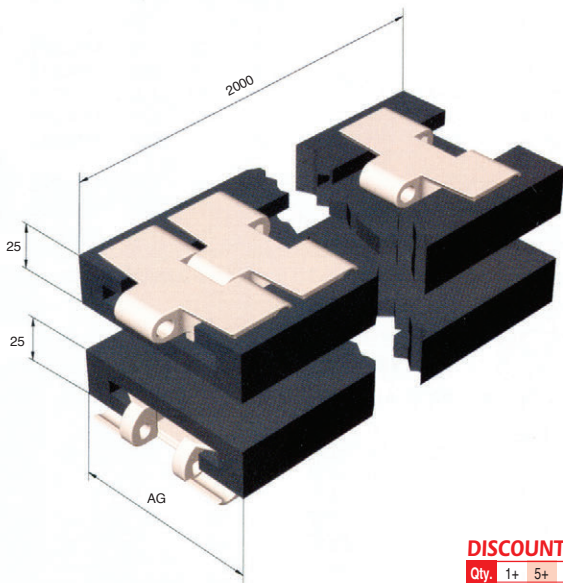

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	For chain	AG (mm)	Length (mm)	Weight (kg)	Price each 1 to 4
GDR880T-82	CAP880T-82 CAP881T-82/SS	100	2000	5,9	247,46 €
GDR880T-114	CAP880T-114 CAP881T-114/SS	130	2000	8,8	321,26 €

Dimensions in mm

Altri prodotti...




HK

Accessorio di serraggio manuale, Serraggio manuale LRX



DOMI80

Accessori di collegamento, Piatto girevole

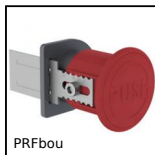

PRFbou

Sistema di chiusura, Pulsante apriporta di emergenza



PCS375S

Pignone a catena - Inox, 9.525 (DIN 06B-1)




NPTF20

Morsetto di collegamento, Distanziale Ø10 a Ø14




DOMI30

Kit di raccordo, Kit di raccordo XY

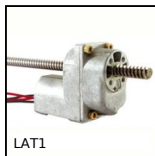

LAT1

Attuatore lineare a motore, 1 ampere

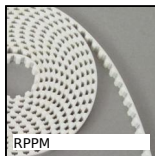


RPPM

Cinghia aperta al metro tipo RPP, RPP5 Poliuretano armatura in acciaio



R_RR

Cremagliera sezione stretta, Acciaio

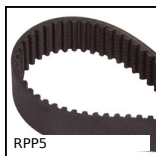


RPP5

Cinghia di trasmissione RPP, RPP5



PGM52-M4

Maniglia a ponte, Alluminio

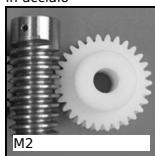

M2

Coppia ruota e vite senza fine, Plastica lavorata (delrin)

Prodotti correlati



CAP880

Catena a tapparella, Stretta serie 880




CAP881

Catena a tapparella, Stretta serie 881



SDG

Supporto con tirante ad occhio, Plastica

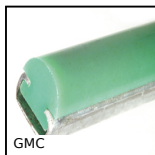

GMC

Guida prodotto laterale tonda, Per imbottigliamento e imballaggio