

Steel brush

GPLAC

For deburring and stripping

- Deburring and cleaning brush for all materials

- Materials:

Twisted galvanised steel


Galvanized steel twist

Steel covering



Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

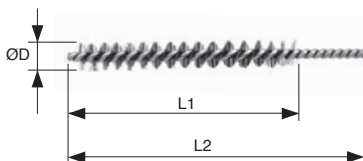

Stripping of a pulley bore

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/AC	5	100	300	✓	10,19 €
GPL8-100/AC	8	100	300	-	6,62 €
GPL10-100/AC	10	100	300	✓	6,62 €
GPL12-100/AC	12	100	300	-	6,75 €
GPL15-100/AC	15	100	300	-	7,00 €
GPL20-100/AC	20	100	300	-	8,27 €
GPL25-100/AC	25	100	300	-	8,27 €

Dimensions in mm

Altri prodotti...



DBL821

Rotella per catena,
Serie 821



CHMX_CHMDX

Albero per riduttore a
ruota e vite senza fine
CHMR e CHM, Albero
se...



LVT

Mini martinetto
motorizzato 4A, 4
ampere



PARF110

Piede senza snodo,
Piede snodato
oscillante fissabile
Ø110



CHN_CHNSS

Catena dritta a maglie
lunghe, Inox



GG3

Ingranaggio dritto
rettificato, Acciaio
trattato



ZHBRA

Ingranaggio conico in
plastica, 1,25:1 2:1
3:1



SDC_{SS}

Boccole di
posizionamento per
pistoncino a molla,
Per puntale da Ø4...



PW_PWG2

Vite senza fine di
precisione, Inox



CMM

Testa a snodo
maschio DIN
ISO12240-4, Acciaio /



GE32


Chiusura a leva rigida
ad anello, Standard



MFBS

Giunto a soffietto
Inox, Inox - con vite a
pressione

Prodotti correlati

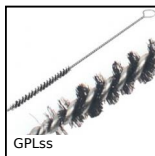


GPL_{SS}

Scovolo, inox




GPL_{br}

Scovolo, ottone

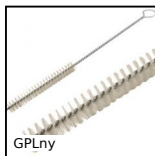

GPL_{ny}

Scovolo, nylon

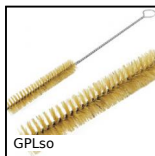

GPL_{so}

Scovolo, seta