

For deburring and stripping  
softer materials

GPL<sub>BR</sub>

- **Deburring and stripping brushes for aluminium, bronze and brass**


- Materials:

Twisted galvanised steel

Brass covering

## Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

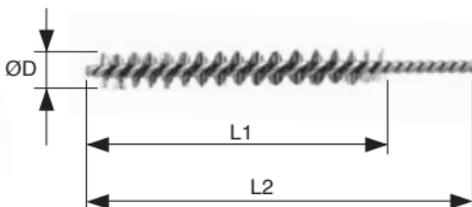

Deburring a trapezoidal nut

## DISCOUNTS


Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/BR	5	100	300	✓	10,03 €
GPL8-100/BR	8	100	300	-	8,40 €
GPL10-100/BR	10	100	300	-	7,56 €
GPL12-100/BR	12	100	300	✓	7,61 €
GPL15-100/BR	15	100	300	✓	7,61 €
GPL20-100/BR	20	100	300	✓	8,07 €
GPL25-100/BR	25	100	300	✓	8,07 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

## Altri prodotti...

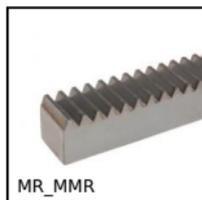

MR\_MMR  
Cremagliera sezione  
metrica, Acciaio



BEAS  
Manopola, stella,  
antistatico




RTN  
Giunto Bowex®, a  
dentatura bombata,  
Nylon



ES  
Support base (tripod),  
Plastic



VAP  
Magnete con foro  
centrale, Con foro  
centrale

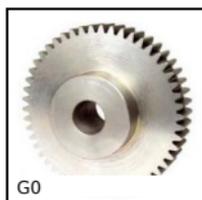

G0  
Ingranaggio dritto  
acciaio, Acciaio  
20NCD2



PPG  
Pistoncino a molla,  
Con flangia di  
fissaggio orizzontale



PM2  
Vite senza fine,  
Acciaio temprato




NPTR  
Morsetto, Regolabile



PT821  
Pignone di trazione,  
Serie 821 e 805




BLH60  
Rinvio angolare a L,  
da 19 a 70 Nm

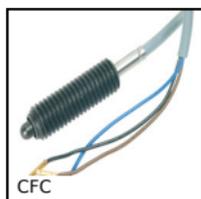


CFC  
Pressore a molla con  
esagono incassato, A  
contatto elettrico


## Prodotti correlati

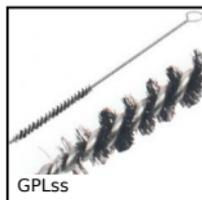


GPLss  
Scovolo, inox

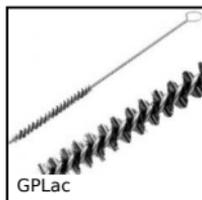

GPLac  
Scovolo, acciaio

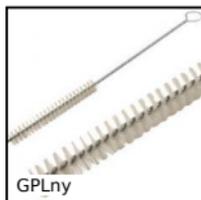

GPLny  
Scovolo, nylon

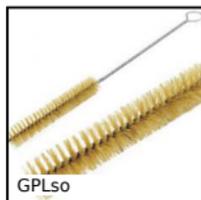

GPLso  
Scovolo, seta