

# Nylon brush

## GPLNY

### For mechanical and soft cleaning

- **Deburring brushes for soft materials**

- **Materials:**




Twisted galvanised steel

Nylon covered

### Applications

- Gentle cleaning of hollow containers  
(tubes, bottles, holes)

- Gentle cleaning of hard-to-reach areas

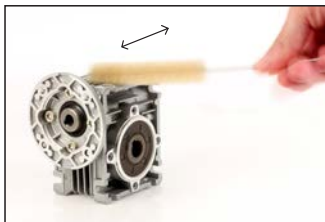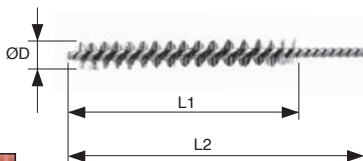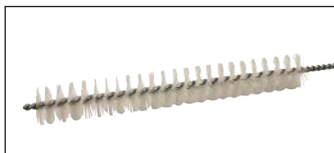

Cleaning the cooling fins of a gearbox

### DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL4-100/NY	4	100	300	✓	6,37 €
GPL6-100/NY	6	100	300	✓	4,19 €
GPL8-100/NY	8	100	300	✓	4,22 €
GPL10-100/NY	10	100	300	✓	4,25 €
GPL12-100/NY	12	100	300	✓	4,28 €
GPL15-100/NY	15	100	300	✓	4,33 €
GPL20-100/NY	20	100	300	✓	4,37 €
GPL25-100/NY	25	100	300	✓	4,45 €
GPL30-100/NY	30	100	300	✓	4,58 €
GPL40-100/NY	40	100	300	✓	4,75 €

Dimensions in mm

## Altri prodotti...



PTGT  
Puleggia folle, Per cinghia trapezoidale



FBL4004\_K32  
Spazzola al metro, Polipropilene nero striato (PP)



PRFSRAD  
Sistema di chiusura per profili alluminio, Serratura doppia rapida a...



FF50  
Riduttore ad alberi paralleli, da 111 a 425 Nm



CHMR30  
Riduttore a ruota e vite senza fine, fino a 28 Nm




BPM  
Pressore a molla con intaglio e puntale a sfera, Inox 303



MHWC  
Giunto flessibile a dischi doppi, Disco doppio



VTLB  
Three-lobed knob, Thermoplastic / Brass or stainless steel insert

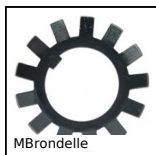

MBrondelle  
Cuscinetti a sfere - Accessorio, Rondella



EV  
Terminale rapido inox per cavi,




NCT  
Giunto di collegamento, Ad




BOXbeta  
Box kit di spine beta, Box kit - beta

## Prodotti correlati

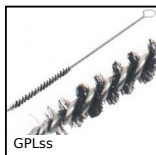


GPLss  
Scovolo, inox

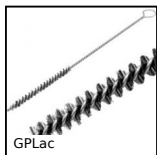

GPLac  
Scovolo, acciaio



GPLbr  
Scovolo, ottone

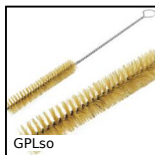

GPLso  
Scovolo, seta