

Nylon brush

GPLNY

For mechanical and soft cleaning

- **Deburring brushes for soft materials**

- **Materials:**




Twisted galvanised steel

Nylon covered

Applications

- Gentle cleaning of hollow containers
(tubes, bottles, holes)

- Gentle cleaning of hard-to-reach areas

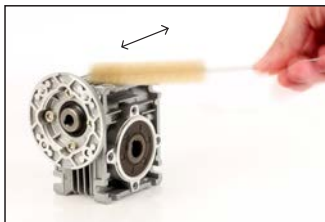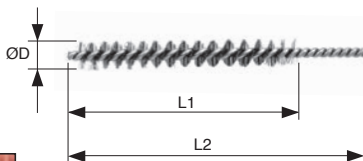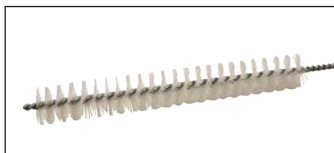

Cleaning the cooling fins of a gearbox

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL4-100/NY	4	100	300	✓	6,37 €
GPL6-100/NY	6	100	300	✓	4,19 €
GPL8-100/NY	8	100	300	✓	4,22 €
GPL10-100/NY	10	100	300	✓	4,25 €
GPL12-100/NY	12	100	300	✓	4,28 €
GPL15-100/NY	15	100	300	✓	4,33 €
GPL20-100/NY	20	100	300	✓	4,37 €
GPL25-100/NY	25	100	300	✓	4,45 €
GPL30-100/NY	30	100	300	✓	4,58 €
GPL40-100/NY	40	100	300	✓	4,75 €


Dimensions in mm

Altri prodotti...



FF10

Riduttore ad alberi paralleli, da 0.78 a 3.70 Nm

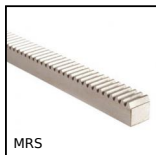

MRS

Cremagliera sezione metrica, Inox



PDD

Pressore a molla sensore di rilevamento, Con asta di comando per int...



AT5-16ECO

Puleggia dentata di posizionamento tipo AT, Serie economica - AT5 al...



P70

Riduttore a ruota e vite senza fine, fino a 164 Nm



PM4

Coppia ruota e vite senza fine, Plastica lavorata (delrin)



TUBE25_25

Tubo quadrato, Alluminio



CHAC4040SS

Cerniera, Quadrata con rivetto e fori



NKX

Cuscinetto combinato senza anello interno,



TCXR

Tenditore per catena automatico, Con



CLQ


Cuscinetti a sfere - Accessorio, Spessori



PR820


Ruota di rinvio, Serie 820 e 815

Prodotti correlati

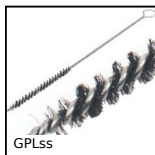

GPLss

Scovolo, inox

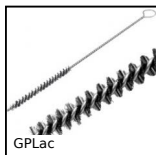


GPLac

Scovolo, acciaio



GPLbr

Scovolo, ottone

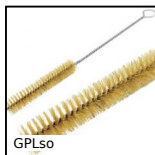

GPLso

Scovolo, seta