

- Brushes for the cleaning and removal of dust

- Materials:



- Twisted galvanised steel
- Natural silk covering

Application

- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas

Advantage

- Anti-static

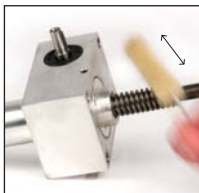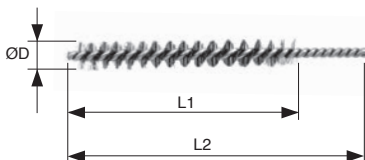

Cleaning of hard-to-reach areas

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL15-100/SO	15	80	300	✓	7,00 €
GPL20-100/SO	20	80	300	-	8,27 €
GPL25-100/SO	25	80	300	✓	7,38 €

Dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel


Altri prodotti...



M1
Coppia ruota e vite senza fine, Acciaio temprato



M1
Coppia ruota e vite senza fine, Plastica lavorata (delrin)

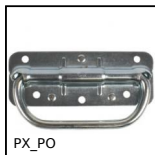

PX_PO
Maniglia - movimentazione manuale, con piastra posteriore



RTT
Calettatore di bloccaggio, Coppia media/elevata



OPFL_OPPM
Accessorio per indicatori, Flangia blocco albero



CLLCLLP
Perno serie lunga, Acciaio - serie lunga



SVT_CH
Martinetto a vite - Montaggio con terminale forato, Console girevole



CHAL3
Cerniera piana, Acciaio



GP
Chiusura a leva molla a trazione compensata,



BLHB50
Rinvio angolare, fino a 30 Nm




AWMP
Albero in alluminio per guida lineare, Alluminio




DTR
Pignone tendicateni, Ruota dentata in plastica

Prodotti correlati

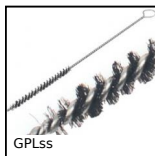


GPLss
Scovolo, inox

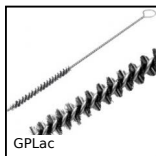

GPLac
Scovolo, acciaio



GPLbr
Scovolo, ottone

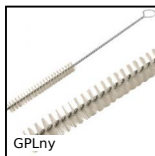

GPLny
Scovolo, nylon