

### - Brushes for the cleaning and removal of dust

#### - Materials:



- Twisted galvanised steel
- Natural silk covering

### Application

- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas

### Advantage

- Anti-static

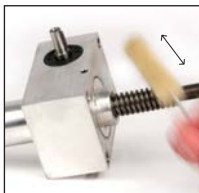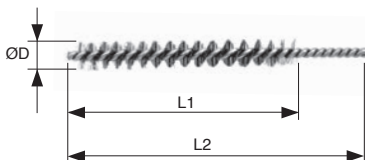

Cleaning of hard-to-reach areas

### DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL15-100/SO	15	80	300	✓	7,00 €
GPL20-100/SO	20	80	300	-	8,27 €
GPL25-100/SO	25	80	300	✓	7,38 €

Dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 €/min  
+ prix appel

## Altri prodotti...



CHM63-MOT

Motoriduttore AC asincrono 0,37 a 1,5kW, 0.37 a 1.5kW




SH4

Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2



BPH

Sfera portante a incastro cilindrico, Forte

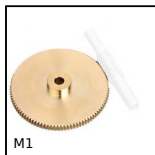

M1

Ruota per vite senza fine, Bronzo



PRT-TO

Corona girevole Iglidur®, Con dentatura esterna-Iglidur®, allumini...



CHML40

Riduttore a ruota e vite senza fine, fino a 57 Nm - Con limitatore d...



SCA\_SS

Serracavo, Inox



BOX-TOR-INCH

Valigetta di guarnizioni toriche in nitrile, For fasteners and fitting



CDPC

Boccola di posizionamento, Acciaio



MFB\_MHB

Ingranaggio conico in plastica stampata, 4:1



CHT


Motore AC asincrono trifase, 0.09kW



KKB-AR


Manicotto a sfere inclinate, Carichi standard / -20° +200°

## Prodotti correlati

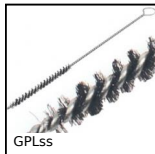

GPLss

Scovolo, inox

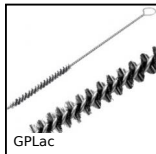


GPLac

Scovolo, acciaio



GPLbr

Scovolo, ottone

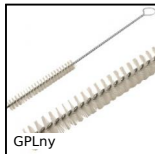

GPLny

Scovolo, nylon