

## Deburring and stripping stainless steel

GPLSS


### - Stainless steel deburring brushes

#### - Materials:

- Twisted galvanised steel
- Stainless steel covering

### Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

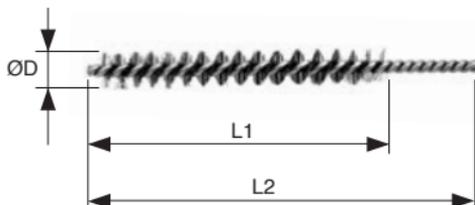

Deburring a gear bore

### DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Overall length L2	Stock*	Price each 1 to 9
GPL5-100/SS	5	100	300	✓	10,03 €
GPL8-100/SS	8	100	300	✓	8,58 €
GPL10-100/SS	10	100	300	✓	7,84 €
GPL12-100/SS	12	100	300	✓	7,84 €
GPL15-100/SS	15	100	300	✓	7,94 €
GPL20-100/SS	20	100	300	✓	8,22 €
GPL25-100/SS	25	100	300	✓	8,29 €


Dimensions in mm

Fax **0 825 88 6000**  
Service 0,15 €/min  
+ prix appel

## Altri prodotti...



NPTF20  
Morsetto di collegamento,  
Distanziale Ø10 a Ø14

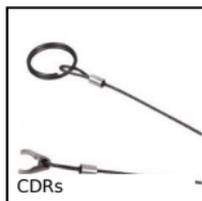

CDRs  
Perno autobloccante,  
Cavo di ritegno



SBS\_L  
Giunzione per catena  
al metro, Maglia di  
giunzione - inox



PCS62SS  
Pignone a catena -  
Inox, 15.875mm (DIN  
08B-1)



GCL  
Guida lineare a sfere -  
Sfere inox, Carello -  
da 516 N a 8396 N



RJA00\_28  
Guarnizione in  
gomma, Da  
agghiacciare



LF  
Cuscinetti a sfere -  
Accessorio, Ghiera di  
regolazione



SVG  
Chiusura a leva  
regolabile, Corsa da  
174mm a 190mm



H0  
Ingranaggio elicoidale  
ad assi incrociati a



PO  
Maniglia a ponte -  
Multi-settore, Foro




PGT  
Accessori per  
pannello, Profilo per




HLUMss  
Impugnatura girevole,  
Inox 316


## Prodotti correlati

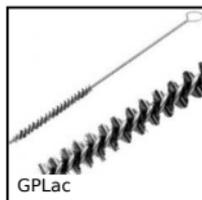


GPLac  
Scovolo, acciaio

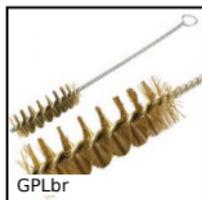

GPLbr  
Scovolo, ottone

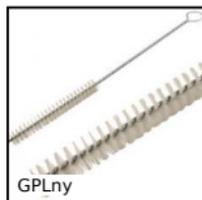

GPLny  
Scovolo, nylon

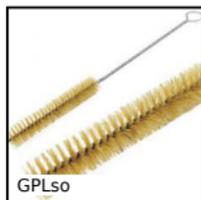

GPLso  
Scovolo, seta