

- Used to block one component in relation to another
- Conforms to standards: (DIN1475) and ISO8744 (DIN1471)
- Material:
Steel 9SMnPb28K
- Supplied by the pack




Advantages


- Only a simple chamfered hole is required, not a precise toleranced bore
- Vibration resistant

Info.

- ISO standard: Overall length is used (DIN standard: the length is measured between the edges)

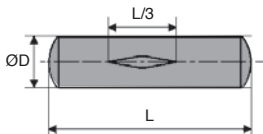

ISO8742

 

ISO8744

DISCOUNTS

Qty	1+	5+	10+	21+
Disc.	List	-10%	-20%	On request

Part number	ØD	L	Standard	Qty per pack	Stock*	Price each 1 to 4
GRP2-14-C/B	2	14	ISO8742	100	-	9,59 €
GRP2.5-24-C/B	2.5	24	ISO8742	100	-	12,00 €
GRP3-12-C/B	3	12	ISO8742	100	✓	10,96 €
GRP3-14-C/B	3	14	ISO8742	100	-	11,23 €
GRP3-18-C/B	3	18	ISO8742	100	✓	11,54 €
GRP3-24-C/B	3	24	ISO8742	100	✓	12,26 €
GRP4-16-C/B	4	16	ISO8742	100	✓	12,86 €
GRP4-24-C/B	4	24	ISO8742	100	✓	13,98 €
GRP5-22-C/B	5	22	ISO8742	100	✓	16,36 €
GRP5-32-C/B	5	32	ISO8742	100	-	22,79 €
GRP8-32-C/B	8	32	ISO8742	50	-	23,68 €
GRP1.5-6-D/B	1.5	6	ISO8744	100	-	8,13 €
GRP2-14-D/B	2	14	ISO8744	100	-	9,59 €
GRP2.5-10-D/B	2.5	10	ISO8744	100	-	10,55 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Altri prodotti...



BOX-TOR-C

Valigetta di guarnizioni toriche in nitrile, 3.00 x 1.50mm a 30.20 x...



TCL-PD

T-Clip - Fissaggio profilati alluminio, Portadocumenti



NT63

Riduttore coassiale a treni paralleli, da 8 to 20 Nm - a treni paral...



RTT

Calettatore di bloccaggio, Coppia media/elevata



DOMI30

Kit di raccordo, Kit di raccordo XY



BOX-SHNA

Dado esagonale - DIN934, Valigetta di dadi acciaio



PRS80

Piede snodato tutto inox Ø80, Ø 80



CHMX_CHMDX

Albero per riduttore a ruota e vite senza fine CHMR e CHM, Albero se...



DCG

Ventosa, silicone



PSG255

Ingranaggio dritto di precisione, Inox 303



RAS

Snodo angolare a 90° DIN71802, Acciaio



PO

Maniglia a ponte - Multi-settore, Foro liscio

Prodotti correlati



SRP

Spina cilindrica ISO8752, elastica ISO 8752