

- Used to block one component in relation to another
- Conforms to standards: (DIN1475) and ISO8744 (DIN1471)
- Material:  
Steel 9SMnPb28K
- Supplied by the pack




### Advantages


- Only a simple chamfered hole is required, not a precise toleranced bore
- Vibration resistant

### Info.

- ISO standard: Overall length is used (DIN standard: the length is measured between the edges)

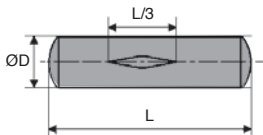

ISO8742

 

ISO8744

### DISCOUNTS

Qty	1+	5+	10+	21+
Disc.	List	-10%	-20%	On request

Part number	ØD	L	Standard	Qty per pack	Stock*	Price each 1 to 4
GRP2-14-C/B	2	14	ISO8742	100	-	9,59 €
GRP2.5-24-C/B	2.5	24	ISO8742	100	-	12,00 €
GRP3-12-C/B	3	12	ISO8742	100	✓	10,96 €
GRP3-14-C/B	3	14	ISO8742	100	-	11,23 €
GRP3-18-C/B	3	18	ISO8742	100	✓	11,54 €
GRP3-24-C/B	3	24	ISO8742	100	✓	12,26 €
GRP4-16-C/B	4	16	ISO8742	100	✓	12,86 €
GRP4-24-C/B	4	24	ISO8742	100	✓	13,98 €
GRP5-22-C/B	5	22	ISO8742	100	✓	16,36 €
GRP5-32-C/B	5	32	ISO8742	100	-	22,79 €
GRP8-32-C/B	8	32	ISO8742	50	-	23,68 €
GRP1.5-6-D/B	1.5	6	ISO8744	100	-	8,13 €
GRP2-14-D/B	2	14	ISO8744	100	-	9,59 €
GRP2.5-10-D/B	2.5	10	ISO8744	100	-	10,55 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

## Altri prodotti...



ZBconique  
Ingranaggio conico  
plastica lavorata  
(delrin), 1:1



GLT16  
Guida telescopica,  
Mini-guida



CHAL3  
Cerniera piana,  
Alluminio




PR881  
Ruota di rinvio, Serie  
881



CHAFR-MINI  
Cerniera, A frizione  
miniatura



MHX  
Manicotto maschiato,  
Esagonale - inox

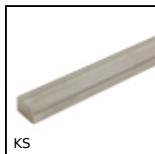

KS  
Chiavetta, Inox - in  
barre



S\_2RS  
Cuscinetto radiale a  
sfere, Inox




RFK28B  
Hypoid gearbox -  
Stainless steel, fino a  
130 Nm



SHA\_PT  
Volantino, Poliammide



BLOC  
Accessori per porte,  
Arresto per porta

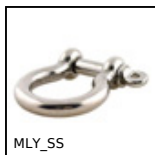

MLY\_SS  
Grillo con chiodo ad  
occhiello, Inox

## Prodotti correlati



SRP  
Spina cilindrica,  
elastica ISO 8752



EP  
Spina cilindrica,  
elastica a spirale ISO  
8750