

Slotted flat headed shoulder screw



Steel

HAS

- Fixes to a frame and allows rotation around the shoulder
- Conforms to DIN 923
- Material:
Burnished steel, resistance class 5.8

Accessory

- Used with HAR captive C washer

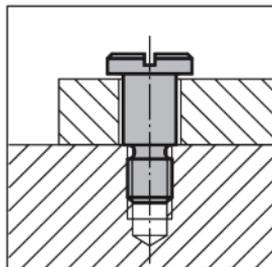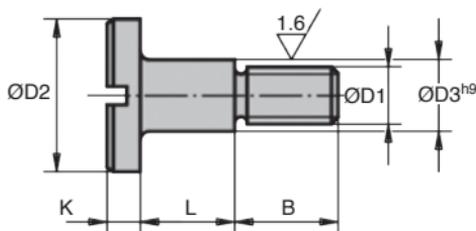

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	ØD1	ØD2	ØD3	L	B	K	Weight (g)	For captive washer	Stock*	Price each 1 to 5
HAS6-8-10	M6	13	8,9	10 +0,07/+0,15	9	3,1	9	HAR9	✓	2,35 €
HAS8-10-12	M8	16	10,9	12 +0,1/+0,2	11	3,8	17	HAR11	✓	2,67 €
HAS10-13-16	M10	20	13,0	16 +0,1/+0,2	13,5	4,6	33	-	-	3,56 €

Dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

165

Altri prodotti...



PRT-TO
Corona girevole Iglidur®, Con dentatura esterna- Iglidur®, allumini...



SVT_CH
Martinetto a vite - Montaggio con terminale forato, Console girevole



EBC
Dado cieco Hygienic Design®, Compatto



NSP
Morsetto base a 90°, Montaggio e regolazione rapidi



TUBE25_25
Tubo quadrato, Alluminio



DCA
Ventosa, silicone




ZG0
Ingranaggio dritto in plastica, Plastica lavorata (delrin)



DOG258
Motoriduttore DC 12V e 24V DC, da 12 a 15 Nm



PTAS0
Piede snodato con base stampata Ø50,

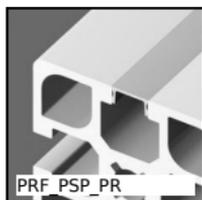

PRF PSP_PR
Profilato di copertura, Da inserire nelle



RBN
Ruota, Rivestimento in gomma - nucleo in



PRF1932
Profilato alluminio standard, 19 x 32 mm

Prodotti correlati



HAR9
Rondella girevole, DIN 6371