

Right angle gearbox

New



HLA24

Torque up to 78 Nm



- Right angle bevel gearbox
- Max speed 1,400 rpm
- Output backlash: 12' to 20'
- Materials:
 - Components: steel
 - Case: cast iron
- Thermal power: 6.7 kW (Heat dissipation capability)

Part number

- When ordering, specify the rotation direction and mounting position by replacing **E** and **B3** in the Part number (see presentation page)

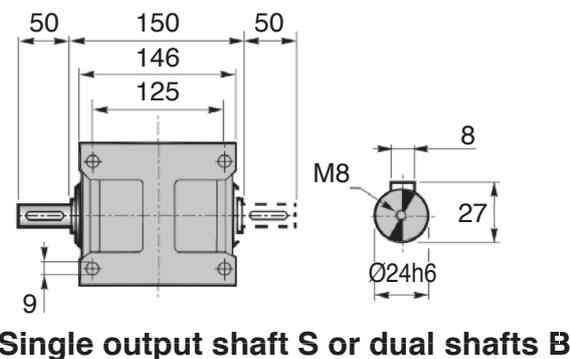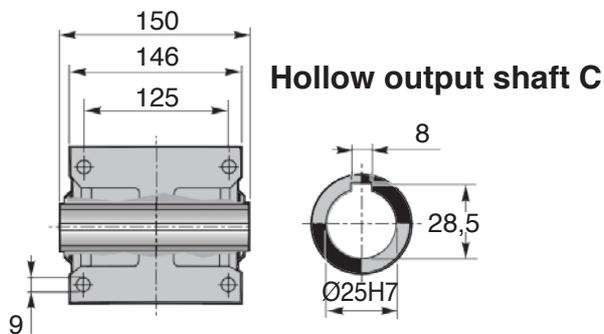

With input shaft

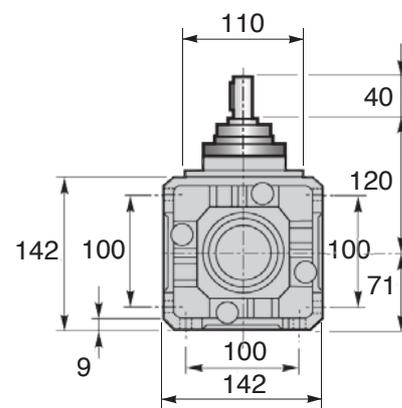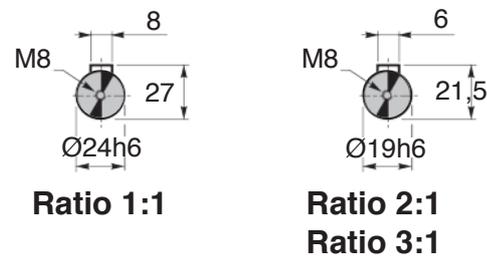

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-5%	On request

Part number	Ratio	Øinput d'entrée (h6)	Input shaft	Max output speed (rpm)	Mechanical output torque* (Nm)	Weight (kg)	Price each
HLA24-1-C-E-B3	1:1	24	hollow	1400	73	14	527,68 €
HLA24-2-C-E-B3	2:1	19	hollow	700	72	14	527,68 €
HLA24-3-C-E-B3	3:1	19	hollow	467	78	14	527,68 €
HLA24-1-S-E-B3	1:1	24	single	1400	73	14	494,39 €
HLA24-2-S-E-B3	2:1	19	single	700	72	14	494,39 €
HLA24-3-S-E-B3	3:1	19	single	467	78	14	494,39 €
HLA24-1-B-E-B3	1:1	24	dual	1400	73	14	525,22 €
HLA24-2-B-E-B3	2:1	19	dual	700	72	14	525,22 €
HLA24-3-B-E-B3	3:1	19	dual	467	78	14	525,22 €

*For maximum torque and a service factor applied, see presentation page - Dimensions en mm


Altri prodotti...



Ruota per trasportatore, Plastica



Chiusura a leva molla a trazione compensata, Standard (GP75)

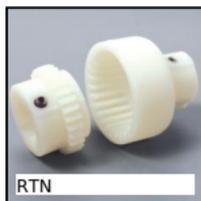

Giunto Bowex®, a dentatura bombata, Nylon



Piedino antivibrante cilindrico, Acciaio



Manopola, stella, antibatterico



Molla di compressione al metro acciaio, al metro



Sealed flange bearing unit for Food Industry, cover



Tavola di posizionamento verticale manuale, 20kg



Volantino zigrinato a serraggio rapido, Zigrinato



Magnete, Con foro maschiato



Rondella sferica - DIN6319, convessa



Piedino antivibrante conico silicone, Fissaggio maschio

Prodotti correlati



Rinvio angolare a dentatura spiroidale, Fino a 78Nm



Rinvio angolare a dentatura spiroidale, Fino a 182Nm