

# Right angle gearbox

New




## HLA24

Torque up to 78 Nm



- Right angle bevel gearbox
- Max speed 1,400 rpm
- Output backlash: 12' to 20'
- Materials:
  - Components: steel
  - Case: cast iron
- Thermal power: 6.7 kW (Heat dissipation capability)

### Part number

- When ordering, specify the rotation direction and mounting position by replacing **E** and **B3** in the Part number (see presentation page)

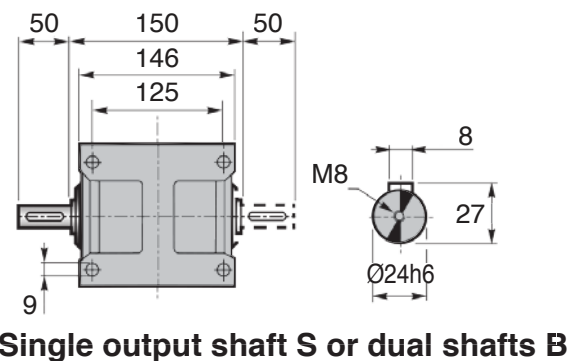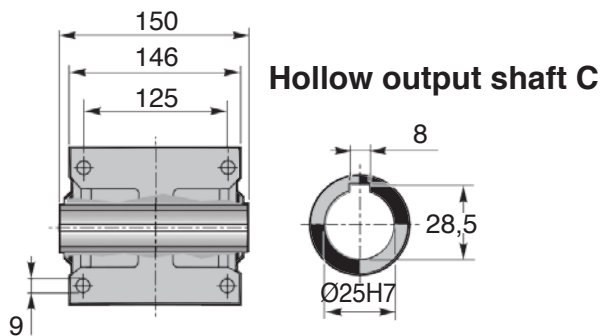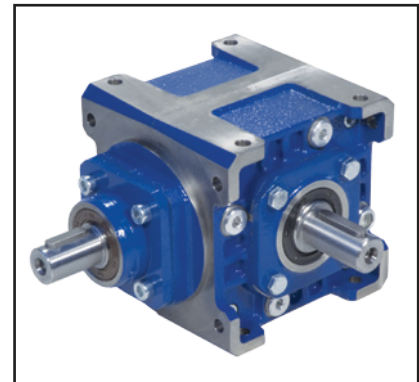

With input shaft

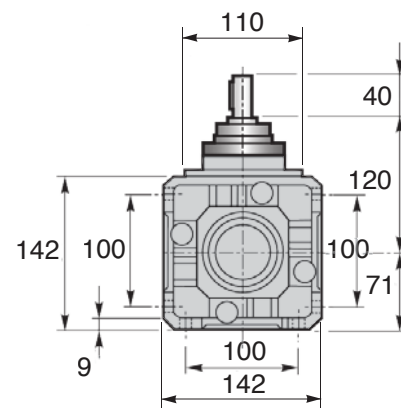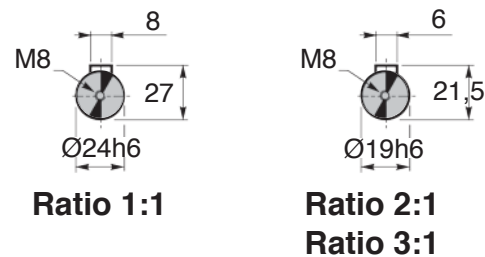

### DISCOUNTS

<b>Qty</b>	1+	2+	4+
<b>Disc.</b>	List	-5%	On request

Part number	Ratio	Øinput d'entrée (h6)	Input shaft	Max output speed (rpm)	Mechanical output torque* (Nm)	Weight (kg)	Price each
HLA24-1-C-E-B3	1:1	24	hollow	1400	73	14	527,68 €
HLA24-2-C-E-B3	2:1	19	hollow	700	72	14	527,68 €
HLA24-3-C-E-B3	3:1	19	hollow	467	78	14	527,68 €
HLA24-1-S-E-B3	1:1	24	single	1400	73	14	494,39 €
HLA24-2-S-E-B3	2:1	19	single	700	72	14	494,39 €
HLA24-3-S-E-B3	3:1	19	single	467	78	14	494,39 €
HLA24-1-B-E-B3	1:1	24	dual	1400	73	14	525,22 €
HLA24-2-B-E-B3	2:1	19	dual	700	72	14	525,22 €
HLA24-3-B-E-B3	3:1	19	dual	467	78	14	525,22 €

\*For maximum torque and a service factor applied, see presentation page - Dimensions en mm

## Altri prodotti...



CDGamme  
Molla di compressione  
DIN2095, DIN 2095



CHTRP  
Riduttore a rinvio  
angolare a L o a T,  
fino a 75,7 Nm



PW\_PWG05  
Ruota di precisione,  
Bronzo



PRES7HR  
Pressa manuale da  
banco, Pressione fino  
a 700kg



WTM  
Rondella per  
serraggio - DIN6340,  
Acciaio



PTA50  
Piede snodato con  
base stampata Ø50,  
4000N



BTESS  
Tenditore automatico  
universale per  
tenditore, Per  
ambienti aggressivi




LVT  
Mini martinetto  
motorizzato 1A, 1  
ampere



CHAGC-AL  
Cerniera ad avvitare,  
Sfilabile



RCC\_RCX  
Rondella sferica -  
DIN6319, convessa

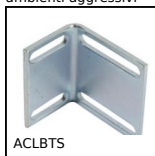

ACLBT5  
Sistema di chiusura  
per profili alluminio,  
Squadra per blocca  
porta ...



RURp  
Rotella girevole con  
piastra, Poliuretano -  
Mozzo alluminio (Ultra  
S...

## Prodotti correlati



HLC24  
Rinvio angolare a  
dentatura spiroidale,  
Fino a 78Nm



HLA28  
Rinvio angolare a  
dentatura spiroidale,  
Fino a 182Nm