

# HTD type tooth bar stock

 


## HTD5M-BAR

Aluminium




- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodising
- Finish : Supplied not anodised



### Info.

- We are unable to modify this product

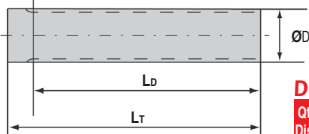

**-30%\*\***

### DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	List -25%	On request	

Part number	Z Teeth	ØD External	Length of teeth L <sub>b</sub>	Total length L <sub>T</sub>	Price each 1 to 5
12HTD5M-BAR	12	17,96	150	160	8,52 €
13HTD5M-BAR	13	19,55	150	160	9,31 €
14HTD5M-BAR	14	21,14	175	200	11,85 €
15HTD5M-BAR	15	22,73	175	200	13,02 €
16HTD5M-BAR	16	24,33	175	200	14,16 €
17HTD5M-BAR	17	25,92	175	200	14,23 €
18HTD5M-BAR	18	27,51	200	200	16,92 €
19HTD5M-BAR	19	29,10	200	200	18,49 €
20HTD5M-BAR	20	30,69	200	200	19,95 €
21HTD5M-BAR	21	32,28	200	200	20,80 €
22HTD5M-BAR	22	33,88	200	200	21,66 €
23HTD5M-BAR	23	35,47	200	200	23,30 €
24HTD5M-BAR	24	37,06	200	200	25,02 €
25HTD5M-BAR	25	38,65	200	200	26,84 €
26HTD5M-BAR	26	40,24	200	200	29,63 €
27HTD5M-BAR	27	41,83	200	200	29,77 €
28HTD5M-BAR	28	43,42	200	200	32,84 €
30HTD5M-BAR	30	46,61	200	200	35,08 €
32HTD5M-BAR	32	49,79	200	200	37,44 €
34HTD5M-BAR	34	52,97	200	200	41,12 €
36HTD5M-BAR	36	56,16	200	200	47,36 €
38HTD5M-BAR	38	59,34	200	200	50,29 €
40HTD5M-BAR	40	62,52	200	200	54,65 €
42HTD5M-BAR	42	65,71	200	200	59,14 €
44HTD5M-BAR	44	68,89	200	200	70,04 €
45HTD5M-BAR	45	70,48	200	200	71,32 €
48HTD5M-BAR	48	75,26	200	200	78,46 €
50HTD5M-BAR	50	78,44	200	200	87,46 €
60HTD5M-BAR	60	94,36	200	200	118,62 €
72HTD5M-BAR	72	113,45	200	200	167,10 €

Dimensions in mm

## Altri prodotti...



T5M T10M

Cinghia aperta al metro tipo T, T5 Poliuretano armatura in acciaio



ADL\_M

Anello di sollevamento, Inox



HTD5M\_09

Puleggia dentata di trasmissione tipo HTD, HTD5 Acciaio



PM3

Coppia ruota e vite senza fine, Acciaio temprato



EHD16

Riduttore coassiale, da 210 a 380 Nm



BTESS

Tenditore automatico universale per tenditore, Per ambienti aggressivi



CHA1056\_U20

Cerniera ad avvitare, Sezione 76x50



PAT123

Piede snodato con base lamiera Ø123, Ø 123



BABV

Ball lock pins lockable, Stainless steel



PTA50ssEB

Piede snodato con base stampata Ø50, Piede snodato



SUP

Calettatore di bloccaggio autocentrante acciaio,



E15

Riduttore a rinvio angolare, da 0.40 a 2.53 Nm

## Prodotti correlati



HTD8M-BAR

Barra dentata per cinghia RPP, HTD8