

- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Steel C40




### Info.

- We are unable to modify this product



**-30%\*\***

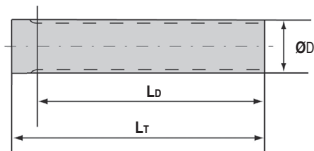


### DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

Part number	Z Teeth	ØD External	Length of teeth L <sub>b</sub>	Total length L <sub>T</sub>	Price each 1 to 5
18HTD8M-BAR	18	44,47	200	200	40,51 €
19HTD8M-BAR	19	47,01	200	200	43,29 €
20HTD8M-BAR	20	49,56	200	200	45,65 €
21HTD8M-BAR	21	52,11	200	200	47,51 €
22HTD8M-BAR	22	54,65	200	200	49,83 €
23HTD8M-BAR	23	57,20	200	200	52,15 €
24HTD8M-BAR	24	59,75	200	200	54,47 €
25HTD8M-BAR	25	62,29	200	200	55,86 €
26HTD8M-BAR	26	64,84	200	200	60,54 €
28HTD8M-BAR	28	69,93	200	200	66,61 €
30HTD8M-BAR	30	75,03	200	200	75,89 €
32HTD8M-BAR	32	80,12	200	200	88,10 €
34HTD8M-BAR	34	85,21	200	200	95,92 €
35HTD8M-BAR	35	87,76	200	200	106,27 €
36HTD8M-BAR	36	90,30	200	200	111,45 €
38HTD8M-BAR	38	95,40	200	200	124,45 €
40HTD8M-BAR	40	100,49	200	200	136,33 €
44HTD8M-BAR	44	110,67	200	200	161,75 €
48HTD8M-BAR	48	120,86	200	200	189,24 €

Dimensions in mm

## Altri prodotti...

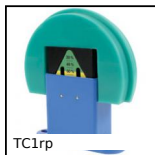

TC1rp  
Tenditore per catena automatico, Con pattino 180°



NRV  
Morsetto incrociato, Montaggio e regolazione rapidi



CHT  
Motore AC asincrono trifase, 1.1 a 1.85kW



ACLEPP  
Angolare, 2 fori




FAD  
Piede snodato semplice, Piede inclinabile senza suola antiscivolo



NPTR  
Morsetto, Regolabile



NTMbr  
Grano punta in ottone, punta in ottone

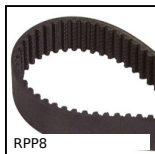

RPP8  
Cinghia di trasmissione RPP, RPP8



EX  
Albero per riduttori E, Albero doppio per



PMC48\_M8  
Supporto antivibrante a campana, Piastra a



LFM  
Vite trapezoidale acciaio, Acciaio



CHAPAM  
Cerniera a testa piatta a saldare, Acciaio

## Prodotti correlati



HTD5M-BAR  
Barra dentata per cinghia RPP, HTD5