 



- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Steel C40



### Info.

- We are unable to modify this product

**-30%\*\***

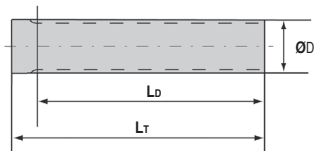

### DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

Part number	Z Teeth	ØD External	Length of teeth L <sub>D</sub>	Total length L <sub>T</sub>	Price each 1 to 5
18HTD8M-BAR	18	44,47	200	200	40,51 €
19HTD8M-BAR	19	47,01	200	200	43,29 €
20HTD8M-BAR	20	49,56	200	200	45,65 €
21HTD8M-BAR	21	52,11	200	200	47,51 €
22HTD8M-BAR	22	54,65	200	200	49,83 €
23HTD8M-BAR	23	57,20	200	200	52,15 €
24HTD8M-BAR	24	59,75	200	200	54,47 €
25HTD8M-BAR	25	62,29	200	200	55,86 €
26HTD8M-BAR	26	64,84	200	200	60,54 €
28HTD8M-BAR	28	69,93	200	200	66,61 €
30HTD8M-BAR	30	75,03	200	200	75,89 €
32HTD8M-BAR	32	80,12	200	200	88,10 €
34HTD8M-BAR	34	85,21	200	200	95,92 €
35HTD8M-BAR	35	87,76	200	200	106,27 €
36HTD8M-BAR	36	90,30	200	200	111,45 €
38HTD8M-BAR	38	95,40	200	200	124,45 €
40HTD8M-BAR	40	100,49	200	200	136,33 €
44HTD8M-BAR	44	110,67	200	200	161,75 €
48HTD8M-BAR	48	120,86	200	200	189,24 €

Dimensions in mm

## Altri prodotti...




GE32  
Chiusura a leva rigida  
ad anello, Standard



RFVcap  
Coperchio di  
protezione inox,  
Coperchio di  
protezione chiuso



PRF\_PSA  
Rotella per profilo  
alluminio, Albero per  
guida

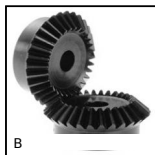

B  
Ingranaggio conico -  
Acciaio 60C40, 1:1



HW\_HT  
Guida su semi-binari,  
Ruota



SVT15  
Martinetto a vite - Vite  
traslante, Vite  
traslante



YG1  
Ingranaggio dritto  
PRESTAZIONE, Acciaio  
35NCD6



T25-6ECO  
Puleggia dentata di  
posizionamento tipo  
T, Serie economica -  
T2.5 al...



CHT  
Motore AC asincrono  
trifase, 0.09kW



TFR  
Tenditore rigido, Fisso



SSDB  
Ingranaggio conico  
inox, 2:1



CLG2  
Ingranaggio dritto in  
plastica stampata,  
Nylon stampato

## Prodotti correlati



HTD5M-BAR  
Barra dentata per  
cinghia RPP, HTD5