



Cylindrical polymer bush


The speed specialist

JSM

- **Material:** iglidur® J, see JFM bushes
- Not sold individually, please contact us for details

Assembly

- Recommended assembly tolerances shaft h9, housing bore-size H7
- Shaft tr. 50 HRC, surface roughness 0.8-2 µm

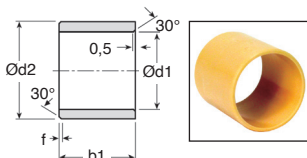

Options

- Bore diameter up to 50mm

DISCOUNTS

Qty	1+	10+	25+	50+	100+	200+	500+
Disc.	List	-10%	-25%	-40%	-50%	-60%	On request

Part number	Ød1	Ød2	b1 (h13)	f	Stock*	Price each 1 to 9
JSM0104-02	1,5 ^{+0,014 +0,054}	4,0	2,0	0,3	-	2,74 €
JSM0205-02	2,0 ^{+0,014 +0,054}	5,0	2,0	0,3	-	2,87 €
JSM0206-02	2,5 ^{+0,020 +0,080}	6,0	2,5	0,3	-	On request
JSM0304-05	3,0 ^{+0,014 +0,054}	4,5	5,0	0,3	✓	3,58 €
JSM0308-04	3,0 ^{+0,020 +0,080}	8,0	4,0	0,3	-	5,33 €
JSM0308-05	3,0 ^{+0,020 +0,080}	8,0	5,0	0,3	-	4,53 €
JSM0405-04	4,0 ^{+0,020 +0,068}	5,5	4,0	0,3	✓	2,92 €
JSM0507-05	5,0 ^{+0,020 +0,068}	7,0	5,0	0,3	✓	3,00 €
JSM0608-06	6,0 ^{+0,020 +0,068}	8,0	6,0	0,5	✓	3,65 €
JSM0608-10	6,0 ^{+0,020 +0,068}	8,0	10,0	0,5	✓	3,90 €
JSM0810-08	8,0 ^{+0,025 +0,083}	10,0	8,0	0,5	✓	3,00 €
JSM0810-10	8,0 ^{+0,025 +0,083}	10,0	10,0	0,5	✓	3,71 €
JSM0810-12	8,0 ^{+0,025 +0,083}	10,0	12,0	0,5	✓	2,74 €
JSM0810-16	8,0 ^{+0,025 +0,083}	10,0	16,0	0,5	✓	3,99 €
JSM1012-05	10,0 ^{+0,025 +0,083}	12,0	5,0	0,5	✓	3,00 €
JSM1012-08	10,0 ^{+0,025 +0,083}	12,0	8,0	0,5	✓	3,06 €
JSM1012-15	10,0 ^{+0,025 +0,083}	12,0	15,0	0,5	✓	4,09 €
JSM1012-20	10,0 ^{+0,025 +0,083}	12,0	20,0	0,5	✓	4,28 €
JSM1014-16	10,0 ^{+0,025 +0,083}	14,0	16,0	0,5	-	3,83 €
JSM1016-10	10,0 ^{+0,025 +0,083}	16,0	10,0	0,5	-	3,90 €
JSM1016-16	10,0 ^{+0,025 +0,083}	16,0	16,0	0,5	-	4,37 €
JSM1214-08	12,0 ^{+0,032 +0,102}	14,0	8,0	0,8	✓	3,32 €
JSM1214-09	12,0 ^{+0,032 +0,102}	14,0	9,0	0,8	-	3,32 €
JSM1214-10	12,0 ^{+0,032 +0,102}	14,0	10,0	0,8	✓	3,32 €
JSM1214-15	12,0 ^{+0,032 +0,102}	14,0	15,0	0,8	✓	4,20 €
JSM1416-10	14,0 ^{+0,032 +0,102}	16,0	10,0	0,8	-	3,65 €
JSM1416-15	14,0 ^{+0,032 +0,102}	16,0	15,0	0,8	-	3,71 €
JSM1416-25	14,0 ^{+0,032 +0,102}	16,0	25,0	0,8	-	4,37 €
JSM1418-18	14,0 ^{+0,032 +0,102}	18,0	18,0	0,8	-	4,37 €
JSM1517-12	15,0 ^{+0,032 +0,102}	17,0	12,0	0,8	✓	4,28 €
JSM1517-20	15,0 ^{+0,032 +0,102}	17,0	20,0	0,8	-	4,09 €
JSM1618-12	16,0 ^{+0,032 +0,102}	18,0	12,0	0,8	✓	4,81 €
JSM1618-20	16,0 ^{+0,032 +0,102}	18,0	20,0	0,8	✓	4,81 €
JSM1820-20	18,0 ^{+0,032 +0,102}	20,0	20,0	0,8	-	5,78 €
JSM2023-20	20,0 ^{+0,040 +0,124}	23,0	20,0	0,8	-	5,83 €
JSM2023-25	20,0 ^{+0,040 +0,124}	23,0	25,0	0,8	✓	5,70 €
JSM2026-30	20,0 ^{+0,040 +0,124}	26,0	30,0	0,8	✓	7,37 €
JSM2427-25	24,0 ^{+0,032 +0,102}	27,0	25,0	0,8	-	7,27 €
JSM2528-30	25,0 ^{+0,040 +0,124}	28,0	30,0	0,8	✓	9,97 €
JSM2630-20	26,0 ^{+0,040 +0,124}	30,0	25,0	0,8	-	6,45 €

*Depending on availability - Dimensions in mm