

# Conical elasto buffer for foodstuff sector



## E-KONBLU

## Female mounting

- Rubber buffer suitable for use in the food industry
- FDA compliant
- Materials :
  - Frame: 316 stainless steel
  - Cylinder: FDA-compliant blue silicon
- Medium hardness, Shore 55A
- Temperature range : -30 °C to +180 °C

stainless steel


NEW!

For foodstuff industry



### Applications

- End stop
- Supporting foot

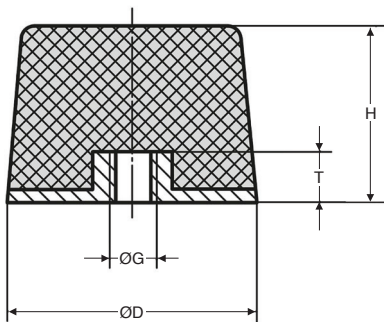

### DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	10%	-20%	On request

Part number	ØG	ØD	H	T	Stiffness (N/mm)	Load (N)	Price each 1 to 5
E-KON6-25-17/SS/BLU	M6	25	17	6	102	571	
E-KON8-30-15/SS/BLU	M8	30	15	8	185	1036	
E-KON10-50-17/SS/BLU	M10	50	17	10	677	3554	

Dimensions in mm



# Conical elasto buffer for foodstuff sector

Male mounting

D-KONBLU

- Rubber buffer suitable for use in the food industry
- FDA compliant
- Materials:
  - Frame: 316 stainless steel
  - Cylinder: FDA-compliant blue silicon
- Medium hardness, Swhore 55A
- Temperature range: -30 °C to +180 °C



## Applications

- End stop
- Supporting foot

stainless steel

NEW!

For foodstuff industry

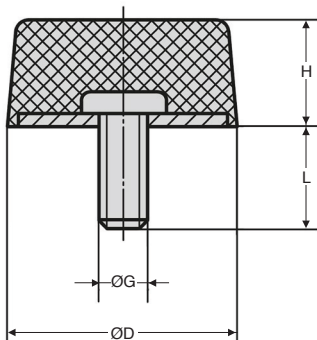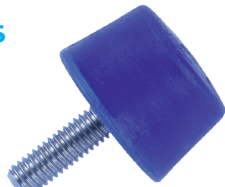

## DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	10%	-20%	On request

Part number	ØG	ØD	H	L	Stiffness (N/mm)	Load (N)	Price each 1 to 5
D-KON6-25-17/SS/BLU	M6	25	17	18	80	448	
D-KON8-30-15/SS/BLU	M8	30	15	20	265	1530	
D-KON10-50-17/SS/BLU	M10	50	17	28	640	3584	

Dimensions in mm

## Altri prodotti...



BABV

Ball lock pins lockable  
, Stainless steel



CHML40

Riduttore a ruota e  
vite senza fine, fino a  
57 Nm - Con  
limitatore d...




KGS

Vite a ricircolo di sfere  
al metro, Vite a sfere  
rullata, al metro



RBNtc

Ruota girevole a foro  
centrale, Acciaio -  
caucciù

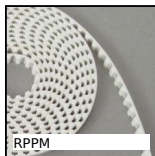

RPPM

Cinghia aperta al  
metro tipo RPP, RPP8  
Poliuretano armatura  
in acciaio



CLG1

Ingranaggio dritto in  
plastica stampata ,  
Nylon stampato



SDG\_SS

Supporto con tirante  
ad occhio, Inox



RDE-W

Rondella di tenuta  
Hygienic Usit®, Inox -  
EPDM bianco



PR40

Piede fissabile con  
snodo - poliammide, Ø



BLHM40

Rinvio angolare, fino a  
10.3 Nm



BAN

Connettore / supporto  
per profili alluminio,



PHTss

Maniglia a ponte, Fino  
a 250°C

## Prodotti correlati



DPAK\_DKON

Piedino antivibrante  
parabolico, Acciaio



D-PAR\_SS

Piedino antivibrante  
parabolico, inox



DKONSL

Piedino antivibrante  
conico silicone,  
Fissaggio maschio



DPAK\_DKON

Piedino antivibrante  
parabolico, Acciaio