

KS KSss

Acciaio C45 o inox 316

 

- Da tagliare alla lunghezza desiderata
- Conforme a DIN6880

Materiali

Acciaio C45 (Resistenza alla rottura

50kg/mm² mini)

Inox 316Ti (X6CrNiMoTi17-12-2)

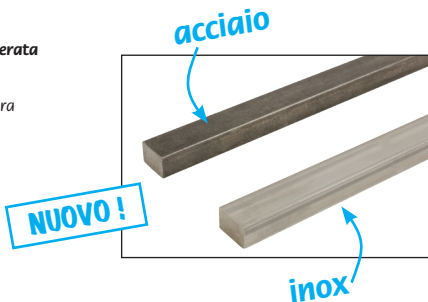

SCONTI PER QUANTITÀ

Qtà	1+	6+	20+
Sc.	Prezzo	-15%	Su richiesta

Codice	W (h9)	H (h11)	L (mm)	Stock*		Prezzo unit da. 1 a 5	
				Acciaio	Inox	Acciaio	Inox
KS2-500	-	2	2	500	✓	-	5,92 € -
KS3-500	-	3	3	500	✓	-	5,10 € -
KS4-500	-	4	4	500	✓	-	6,12 € -
KS5-500	KS5-500/SS	5	5	500	✓	✓	7,85 € 57,98 €
KS6-500	KS6-500/SS	6	6	500	✓	✓	10,05 € 59,76 €
KS8-500	-	8	8	500	✓	-	11,67 € -
KS87-500	KS87-500/SS	8	7	500	✓	-	10,04 € 84,71 €
KS10-500	-	10	10	500	✓	-	17,06 € -
KS108-500	KS108-500/SS	10	8	500	✓	✓	14,28 € 118,32 €
KS12-500	-	12	12	500	✓	-	22,37 € -
KS128-500	KS128-500/SS	12	8	500	✓	-	12,82 € 142,40 €
KS14-500	-	14	14	500	-	-	26,41 € -
KS149-500	KS149-500/SS	14	9	500	✓	-	16,83 € 193,80 €
KS1610-500	KS1610-500/SS	16	10	500	✓	-	21,36 € 240,16 €
KS1811-500	KS1811-500/SS	18	11	500	✓	-	26,44 € 287,13 €
KS2012-500	-	20	12	500	✓	-	30,05 € -
KS2214-500	KS2214-500/SS	22	14	500	-	-	38,96 € 431,89 €
KS2514-500	-	25	14	500	✓	-	44,22 € -

*Nei limiti delle disponibilità - Dimensioni in mm