

Spring return latch




LRR

Steel or stainless steel


- **Spring loaded single bolt**
- Rolled knot hinge
- **Material:**
White galvanized steel
Stainless steel 304

Advantages

- Simple locking
- Retractable pivot

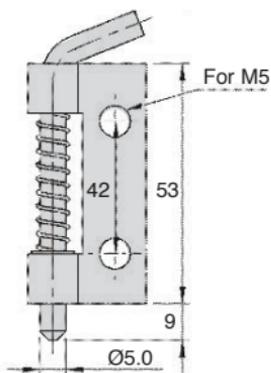

Right handed

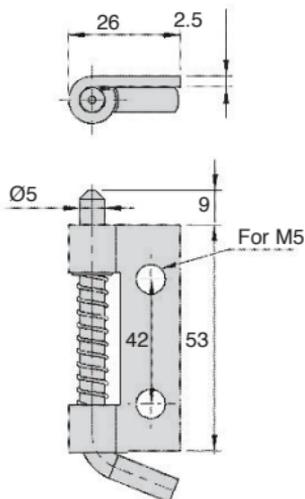

Left handed

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-	-10%	On request

Part N°	Version	Stock*	Price each 1 to 49
Steel version			
LRR-53-26/D	Right	-	2,82 €
LRR-53-26/G	Left	-	2,82 €
Stainless steel version			
LRR-53-26/G/SS	Left	-	5,64 €
LRR-53-26/D/SS	Right	-	5,64 €

All dimensions in mm

Altri prodotti...



VTHbr

Vite a testa esagonale
- DIN933, Ottone



SLHHlok

Bloccaggio a leva, A
leva orizzontale / base
orizzontale



HW_HT

Guida su semi-binari,
Binario



M2

Vite senza fine,
Acciaio non temprato



NPTR

Morsetto, Regolabile



PRF_PSA

Rotella per profilo
alluminio, Albero per
guida



LC

Limitatore di coppia
ad attrito, 190 a 1800
Nm



SUPss

Calettatore di
bloccaggio
autocentrante inox,
Senza ghiera




GB-RA

Ingranaggio dritto
ottone, Ottone



B3PAN

Panamech, Multi-
Beam inox, Inox - con

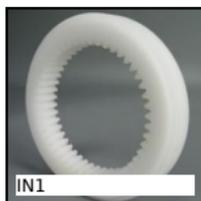

IN1

Ingranaggio interno,
Plastica lavorata



GE32

Chiusura a leva rigida
ad anello, Standard

Prodotti correlati



LRRss

Interblocco di
sicurezza, Chiusura a
molla - inox



LRR

Chiavistello con perno
prismatico, Lucchetto
a molla



LRR-53

Chiavistello con
bloccaggio, Lucchetto
a molla inox



LRR22

Small dimension latch
with locking system,
Aluminium