

Spring return latch




LRR

Steel or stainless steel


- **Spring loaded single bolt**
- Rolled knot hinge
- **Material:**
White galvanized steel
Stainless steel 304

Advantages

- Simple locking
- Retractable pivot

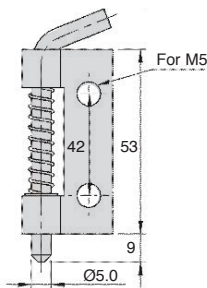

Right handed

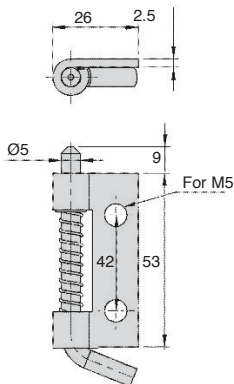

Left handed

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-	-10%	On request

Part N°	Version	Stock*	Price each 1 to 49
Steel version			
LRR-53-26/D	Right	-	2,82 €
LRR-53-26/G	Left	-	2,82 €
Stainless steel version			
LRR-53-26/G/SS	Left	-	5,64 €
LRR-53-26/D/SS	Right	-	5,64 €

All dimensions in mm

Altri prodotti...



PC5505S
Pignone a catena -
Inox, 12.7mm (DIN
08B-1)




PLS
Distanziatore
cilindrico, Inox 303



PRF_PGN
Maniglia e battuta per
porta, Maniglia con
serratura



MHXred
Manicotto di
riduzione, Esagonale -
inox

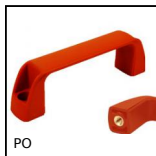

PO
Maniglia a ponte -
Multi-settore,
Foro cieco maschiato



G-ECO
Ingranaggio dritto
acciaio - serie ECO,
Acciaio C45



GAL_25
Rullo per
trasportatore, Senza
cuscinetti a sfere



PRF4590_E
Squadra di giunzione,
PRF4590



BABPass
Perno autobloccante
inox temprato ad
anello, Con



NT63
Riduttore coassiale a
treni paralleli, da 8 to
20 Nm - a treni



BAGSS
Anello di bloccaggio
inox, Inox



PTA100
Piede snodato con
base stampata Ø100,
Ø 100

Prodotti correlati



LRR-53
Chiavistello con
bloccaggio, Lucchetto
a molla acciaio



LRRss
Interblocco di
sicurezza, Chiusura a
molla - inox



LRR
Chiavistello con perno
prismatico, Lucchetto
a molla