

Spring return latch




 
LRR

Steel or stainless steel


- **Spring loaded single bolt**
- Rolled knot hinge
- **Material:**
White galvanized steel
Stainless steel 304

Advantages

- Simple locking
- Retractable pivot

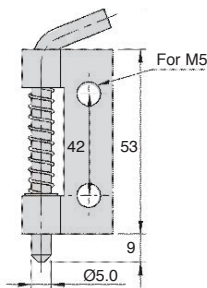

Right handed

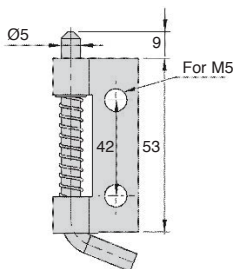

Left handed

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-10%	On request	

Part N°	Version	Stock*	Price each 1 to 49
Steel version			
LRR-53-26/D	Right	-	2,82 €
LRR-53-26/G	Left	-	2,82 €
Stainless steel version			
LRR-53-26/G/SS	Left	-	5,64 €
LRR-53-26/D/SS	Right	-	5,64 €

All dimensions in mm

Altri prodotti...



CM_CO
Attrezzi Hygienic Usit® and Hygienic Design®, Protective inserts f...



SER69K-CLE
Chiusura 1/4 di giro per agroalimentare, Chiave



LRR-53
Chiavistello con bloccaggio, Lucchetto a molla acciaio



BAGO
Anello di bloccaggio, Inox



BLH20
Rinvio angolare a L, da 0.53 a 1.77



BABFCFO
Perno autobloccante, Boccole di fissaggio con flangia cilindrica



DPAR_DKON
Piedino antivibrante parabolico, Acciaio




FR
Inseri filettati, Acciaio



ACL
Elementi di giunzione, Angolare



PR821
Ruota di rinvio, Serie 821 e 805

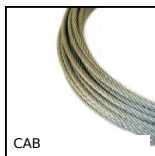

CAB
Cavo di fissaggio, Acciaio galvanizzato



ACAss
Albero scanalato Inox 304, Inox

Prodotti correlati



LRRss
Interblocco di sicurezza, Chiusura a molla - inox



LRR
Chiavistello con perno prismatico, Lucchetto a molla



LRR-53
Chiavistello con bloccaggio, Lucchetto a molla inox



LRR22
Small dimension latch with locking system, Aluminium