

Spring return latch




 
LRR

Steel or stainless steel


- **Spring loaded single bolt**
- Rolled knot hinge
- **Material:**
White galvanized steel
Stainless steel 304

Advantages

- Simple locking
- Retractable pivot

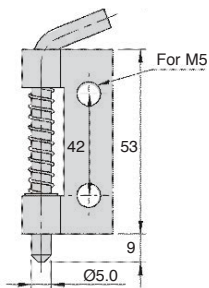

Right handed

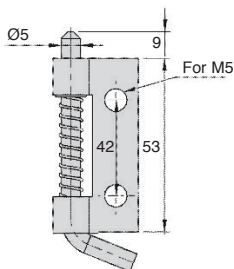

Left handed

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-10%	On request	

Part N°	Version	Stock*	Price each 1 to 49
Steel version			
LRR-53-26/D	Right	-	2,82 €
LRR-53-26/G	Left	-	2,82 €
Stainless steel version			
LRR-53-26/G/SS	Left	-	5,64 €
LRR-53-26/D/SS	Right	-	5,64 €

All dimensions in mm

Altri prodotti...



PTA50

Piede snodato con base stampata Ø50, Ø 50



BLHT50

Rinvio angolare a T, da 11.50 a 30 Nm



ESCON

Accessori per variatore di velocità 5A, Kit 4 cavi motore DC



GE

Chiusura a leva, Miniature



CHMR90

Riduttore a ruota e vite senza fine, fino a 540 Nm



PR820

Ruota di rinvio, Serie 820 e 815



ASH

Anello di sollevamento, dritto a saldare



SCA

Serracavo, Acciaio



ZBRA

Ingranaggio conico in plastica, 1:1



EKN

Giunto a soffietto Gerwah®, da 0.5 a 12Nm



PT821

Pignone di trazione, Serie 821 e 805



WINGbrEcrou

Dado ad alette per serraggio manuale DIN315, Ottone DIN 315

Prodotti correlati



LRR-53

Chiavistello con bloccaggio, Lucchetto a molla acciaio



LRRss

Interblocco di sicurezza, Chiusura a molla - inox



LRR

Chiavistello con perno prismatico, Lucchetto a molla



LRR22

Small dimension latch with locking system, Aluminium