

# Spring return latch




 
## LRR

## Steel or stainless steel


- **Spring loaded single bolt**
- Rolled knot hinge
- **Material:**  
White galvanized steel  
Stainless steel 304

### Advantages

- Simple locking
- Retractable pivot

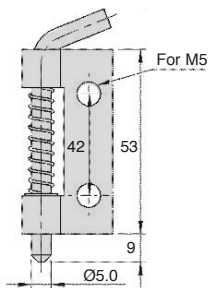

Right handed

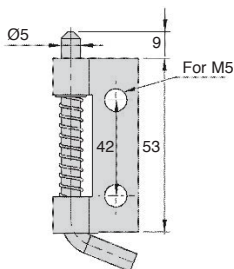

Left handed

### DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-	-10%	On request

Part N°	Version	Stock*	Price each 1 to 49
<b>Steel version</b>			
LRR-53-26/D	Right	-	2,82 €
LRR-53-26/G	Left	-	2,82 €
<b>Stainless steel version</b>			
LRR-53-26/G/SS	Left	-	5,64 €
LRR-53-26/D/SS	Right	-	5,64 €

All dimensions in mm

## Altri prodotti...



LRM

Dado cilindrico in bronzo, Bronzo - 1 filetto



HRV

Sistema di guida su binario a V Simple Select®, Binario con carrello



GLT2-17

Guide telescopiche per montaggio in scanalatura, Estensione parziale



CHA35

Cerniera ad avvitare, Cerniera



SHN

Dado esagonale - DIN934, Acciaio (Class 6|8)



CHAR7520

Cerniera a molla, avvitabile



GGP

Vite ad alette, Tecnopolimero con inserto in acciaio



RCX-6

Rondella sferica - DIN6319, convessa




BSCf

Manopola, Con coppia regolabile




G0

Ingranaggio dritto acciaio, Acciaio

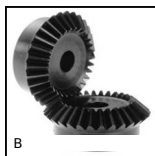

B

Ingranaggio conico - Acciaio 60C40, 1:1

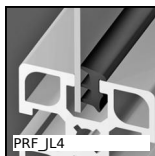

PRF\_JL4

Panel accessories, Guarnizione - Ø4mm

## Prodotti correlati



LRRss

Interblocco di sicurezza, Chiusura a molla - inox



LRR

Chiavistello con perno prismatico, Lucchetto a molla



LRR-53

Chiavistello con bloccaggio, Lucchetto a molla inox



LRR22

Small dimension latch with locking system, Aluminium