

Spring return latch




 
LRR

Steel or stainless steel


- Spring loaded single bolt
- Rolled knot hinge
- Material:
White galvanized steel
Stainless steel 304

Advantages

- Simple locking
- Retractable pivot

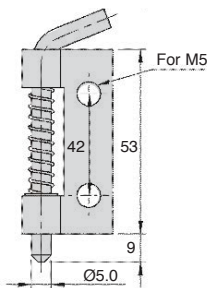

Right handed

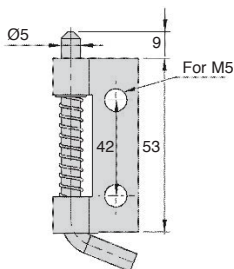

Left handed

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-10%	On request	

Part N°	Version	Stock*	Price each 1 to 49
Steel version			
LRR-53-26/D	Right	-	2,82 €
LRR-53-26/G	Left	-	2,82 €
Stainless steel version			
LRR-53-26/G/SS	Left	-	5,64 €
LRR-53-26/D/SS	Right	-	5,64 €

All dimensions in mm

Altri prodotti...



RTTss

Calettatore di bloccaggio, Coppia media/elevata



DFG

Ventosa, nitrile



AFM

Cuscinetto a collare, Polimero alimentare



SBF

Sealed flange bearing unit for Food Industry, cover



WSRM

Dado cilindrico in polimero, Polimero (Iglidur®) - 1 filetto



PITA

Pistoncino a molla, con maniglia a T



INI

Ingranaggio interno, Acciaio 20NCD2



PRF_CH

Catena porta cavo, Supplied in metre lengths



CHA1056-U4

Cerniera ad avvitare, Aperura 180°



PRF-CHAR-POU

Attrezzi, Carrello attrezzi



DOMI30

Slitta di regolazione Domino 30, Slitta



BABTV

Ball lock pins lockable, Stainless steel

Prodotti correlati



LRR-53

Chiavistello con bloccaggio, Lucchetto a molla acciaio



LRRss

Interblocco di sicurezza, Chiusura a molla - inox



LRR

Chiavistello con perno prismatico, Lucchetto a molla



LRR22

Small dimension latch with locking system, Aluminium