

Spring return latch




 
LRR

Steel or stainless steel


- **Spring loaded single bolt**
- Rolled knot hinge
- **Material:**
White galvanized steel
Stainless steel 304

Advantages

- Simple locking
- Retractable pivot

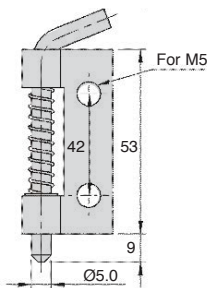

Right handed

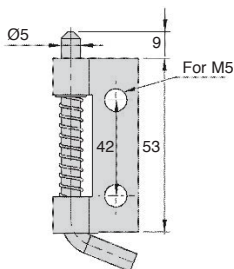

Left handed

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-10%	On request	

Part N°	Version	Stock*	Price each 1 to 49
Steel version			
LRR-53-26/D	Right	-	2,82 €
LRR-53-26/G	Left	-	2,82 €
Stainless steel version			
LRR-53-26/G/SS	Left	-	5,64 €
LRR-53-26/D/SS	Right	-	5,64 €

All dimensions in mm

Altri prodotti...



FBL6000_K19
Spazzola al metro,
Crine di cavallo nero



TBE16
Economic mini-table
with trapezoidal
leadscrew, 5kg



PCLA_T
Maniglia a ripresa,
Plastica



HBM
Guida su semi-binari,
Boccola di regolazione



T5_11
Puleggia dentata di
posizionamento tipo
T, T5 alluminio



IN0
Ingranaggio interno,
Acciaio 20NCD2



EHD08-9
Riduttore coassiale,
da 35 a 50 Nm



BPHF
Sfera portante a
incastro con flangia,
Forte



MET
Cuscinetto cilindrico ,
Bronzo
autolubrificante



BPLF
Sfera portante alta
sporgenza, Leggero



VDS
Bloccaggio scorrevole
per la regolazione,
Bloccaggio rapido per



GB-RA
Ingranaggio dritto
ottone, Ottone
CuZn39Pb3

Prodotti correlati



LRRss
Interblocco di
sicurezza, Chiusura a
molla - inox



LRR
Chiavistello con perno
prismatico, Lucchetto
a molla



LRR-53
Chiavistello con
bloccaggio, Lucchetto
a molla inox



LRR22
Small dimension latch
with locking system,
Aluminium