

Spring return latch




LRR

Steel or stainless steel


- **Spring loaded single bolt**
- Rolled knot hinge
- **Material:**
White galvanized steel
Stainless steel 304

Advantages

- Simple locking
- Retractable pivot

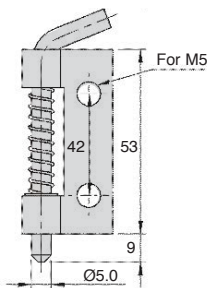

Right handed

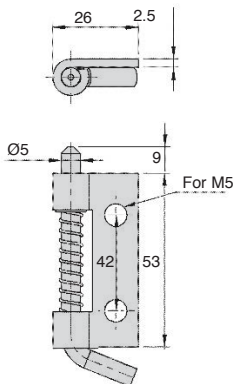

Left handed

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-10%	On request	

Part N°	Version	Stock*	Price each 1 to 49
Steel version			
LRR-53-26/D	Right	-	2,82 €
LRR-53-26/G	Left	-	2,82 €
Stainless steel version			
LRR-53-26/G/SS	Left	-	5,64 €
LRR-53-26/D/SS	Right	-	5,64 €

All dimensions in mm

Altri prodotti...



AC

Pastrina di riscontro,
13mm



CHAE3030PA

Cerniera ad avvitare
estetica quadrata,
Poliammide



PT881

Pignone di trazione,
Serie 881



MEP

Impugnatura cilindrica
libera, Fissa



HW_HT

Guida su semi-binari,
Binario



DOMI80

Kit di raccordo, Kit di
raccordo XZ



CLLCLLP

Forcella serie lunga,
Lunga acciaio



MSP19

Insero con piastrina a
incollare
Masterplate®,
Cilindrico con inse...



PRF_ART

Cerniere e giunti, Con
maniglia di serraggio



FF15

Riduttore ad alberi
paralleli, da 2.20 a 10



PRF_PL_4590

Elementi di giunzione,
Piastra di giunzione -



CHARcav

Cerniera a molla, to
install

Prodotti correlati



LRRss

Interblocco di
sicurezza, Chiusura
a molla - inox



LRR

Chiavistello con perno
prismatico, Lucchetto
a molla



LRR-53

Chiavistello con
bloccaggio, Lucchetto
a molla inox