

Spring loaded latch

Bra


LRR

Plated steel or chromed brass

- **Night latch**
- Inward/outward opening versions available (A+ B versions)
- Materials : Plated steel or chromed brass

Info.

- Part N° LRR-50-A/LC replaces the old reference LRR-50

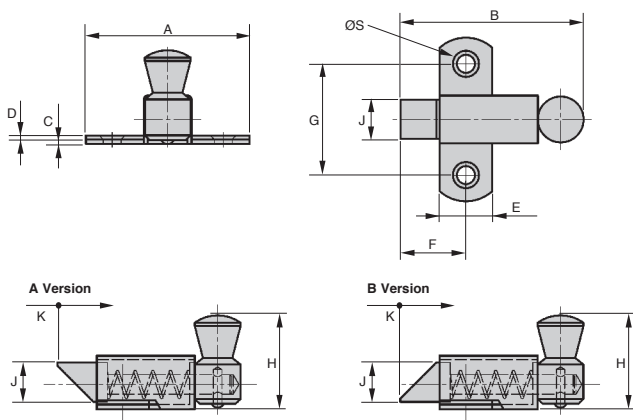


DISCOUNTS

Qty.	1+	51+	101+
Disc.	List -10%	On request	


Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Stock*	Price each 1 to 50	
Version A																
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	18,57 €	
LRR-50-A/LC	50	56	1,5	1,2	16	20	34	27	12	12	4	Brass	75	✓	25,05 €	
Version B																
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	18,57 €	
LRR-50-B/LC	50	56	1,5	1,2	16	20	34	27	12	12	4	Brass	75	-	39,69 €	

*Depending on availability

- Catch for sprung latch LRR
- Materials : Plated steel or chromed brass

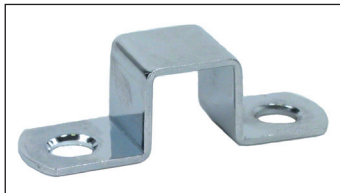

INCREASED
STOCK

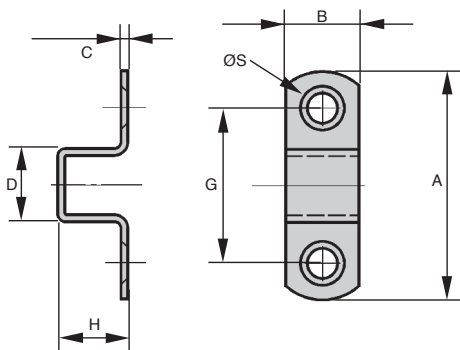

DISCOUNTS

Qty.	1+	51+	101+
Disc.	List	-10%	On request

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock*	Price each 1 to 50
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	2,75 €
LRR-50-GPV/LC	50	16	1,5	16	34	16	4	Brass	13	✓	6,54 €

*Depending on availability

Altri prodotti...



SUA4_L

Giunzione per catena al metro, Maglia di giunzione - acciaio



KKSS

Chiavetta rettangolare , Inox



CHNrb

Catena segnaletica rossa e bianca, Acciaio




LVT

Mini martinetto motorizzato 4A, 4 ampere



DOMI120

Accessori di collegamento, Piastra

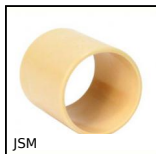

JSM

Cuscinetto cilindrico , Polimero universale



NSB

Supporto standard per manicotto chiuso a sfere, Chiuso - Lungo



SSB

Ingranaggio conico inox, 1:1




RURp

Rotella girevole con piastra, Poliuretano - Mozzo alluminio (Ultra



SHSS

Vite a spalla inox 416, Inox 416 pretrattato

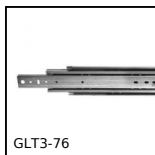

GLT3-76

Guide telescopiche acciaio, Estensione totale



VHTM

Hexagonal headed bolt Hygienic Design®, Inox

Prodotti correlati



LRR

Chiavistello con perno prismatico, Lucchetto a molla