

- **Springloaded bolt can be held in unlocked position**

- It is recommended to combine 1 latch with 1 strike

- Materials:


Body: aluminium 6060T5 clear anodised

Shaft and handle: raw aluminium

Cap: Black PE

Spring: Stainless steel


Strike: aluminium 5754 clear anodised

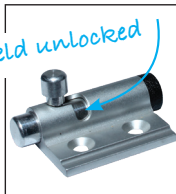


Springloaded bolt





Strike

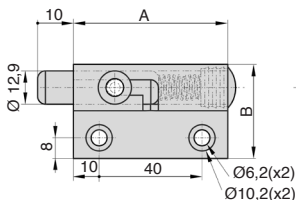

LRR-37-2/ALU

 

LRR-37-1/ALU

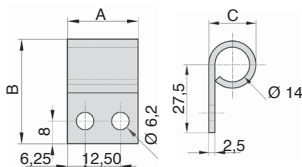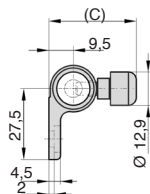

LRR-37-GPV/ALU

DISCOUNT

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	Type	Weight (g)	Stock*	Price each 1 à 9
Springloaded bolt							
LRR-37-2/ALU	60	36,5	34	2	58		
LRR-37-1/ALU	60	36,5	34	1	58		
Strike							
LRR-37-GPV/ALU	25	37	19	-	11		

*Depending on availability - Dimensions in mm

Altri prodotti...



Manicotto a sfere,
Leggera




Aggancio per tirante
chiusura in gomma,
Aggancio



Guida modulabile
Drylin® W, Binario



Coppia ruota e vite
senza fine, Acciaio
temprato

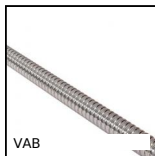

Vite a ricircolo di sfere
al metro, Vite a sfere
rullata, al metro



Accessori per pressa
PRES-3HR e
PRES-4HR, Portapinzine



Cuscinetto a collare ,
Bronzo
autolubrificante
METAFRAM



Supporto per
manicotto, Chiuso -
carico leggero



Boccola di fermo per
perno ad innesto,



Mini sfera portante a
incastro, A incastro



Chiusura a leva
regolabile, Corsa da



Puleggia folle, Perno

Prodotti correlati



Small dimension latch
with locking system,
Aluminium