

- **Springloaded bolt can be held in unlocked position**

- It is recommended to combine 1 latch with 1 strike

- Materials:


Body: aluminium 6060T5 clear anodised

Shaft and handle: raw aluminium

Cap: Black PE

Spring: Stainless steel


Strike: aluminium 5754 clear anodised

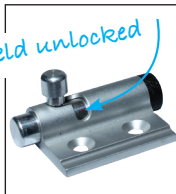


Springloaded bolt





Strike

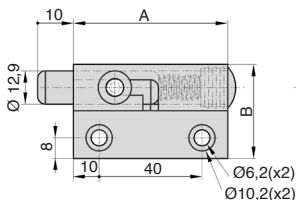

LRR-37-2/ALU

 

LRR-37-1/ALU

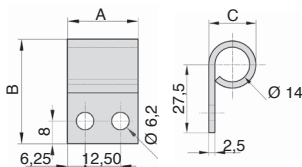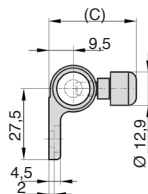

LRR-37-GPV/ALU

### DISCOUNT

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	Type	Weight (g)	Stock*	Price each 1 à 9
<b>Springloaded bolt</b>							
LRR-37-2/ALU	60	36,5	34	2	58		
LRR-37-1/ALU	60	36,5	34	1	58		
<b>Strike</b>							
LRR-37-GPV/ALU	25	37	19	-	11		

\*Depending on availability - Dimensions in mm


## Altri prodotti...



MDB\_MTB  
Ingranaggio conico in  
plastica stampata, 2:1



SERB  
Serratura a camme,  
Serratura a camme

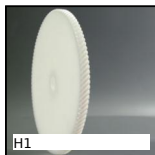

H1  
Ingranaggio elicoidale  
ad assi incrociati a  
90°, Plastica lavorata



GALRUB  
Rullo per  
trasportatore, Caucciù



RAGFLOW  
Rotaaia a rulli  
Floway2®, Rotaaia a  
rulli




PGB  
Attrezzi, Porta attrezzi



R206  
Molla per stampi  
ISO10243, Extra-forte



BPTR  
Tappo per tubo tondo,  
Standard

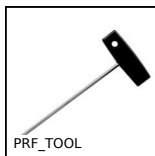

PRF\_TOOL  
Attrezzi, Chiave di  
montaggio



SHSS  
Vite a spalla inox 416,  
Inox 416 pretrattato



BG  
Giunto Oldham, con  
vite a pressione



PW\_PWG05  
Vite senza fine di  
precisione, Inox

## Prodotti correlati



LRR22  
Small dimension latch  
with locking system,  
Aluminium