

 


 
 

- Slam latches for direct closing in hostile environments
- Latch tongue at top
- Resistant to water and cleaning products
- Materials:  
Body and support: 304L stainless steel  
Latch and handle: 303 stainless steel  
Spring: 301 stainless steel

### Advantages

- Openings on the top and mounting face allow easy cleaning (no retention of water or dirt)
- No sharp angles (avoids risk of injury)
- Top mounted handle allows easy opening

### Applications

- Equipment for the food industry
- Animal breeding (hutches, hen-houses)
- Lids for metal enclosures used in humid environments
- Stainless steel strike plate not supplied

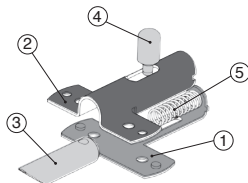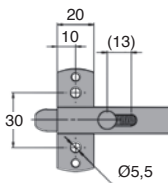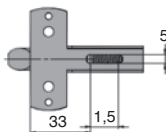

A version



B version

### DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-3%	-5%	-10%	On request

Part number	Latch stroke (mm)	Type	Stock*	Price each 1 to 49
LRR-56-A/SS	12	A version	✓	29,08 €
LRR-56-B/SS	13	B version	✓	29,08 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min  
+ prix appel

Fax

## Altri prodotti...



LQT  
Chiusura a sfera,  
Chiusura rapida



SSDB  
Ingranaggio conico  
inox, 2:1



DB  
Ingranaggio conico in  
acciaio, 2:1



J52  
Riduttore coassiale a  
treni paralleli, da 0.27  
a 0.90 - a treni para...



RLX  
Rullo folle plastica,  
PVC



PAP  
Maniglia e battuta per  
porta, Maniglia  
ergonomica



CHA  
Cerniera, Robusta -  
Apertura 180°



CHAC4040NP  
Cerniera, Quadrata  
con rivetto senza fori



IBJ  
Snodo angolare a  
180°, Acciaio



CCL  
Capocorda ad  
occhiello, Acciaio



PRF\_CLIP\_22  
Clip di fissaggio per  
cavi per profili  
alluminio, Per cavi



PP35  
Riduttore a ruota e  
vite senza fine, da  
2.20 a 4.10 Nm

## Prodotti correlati



LRR  
Chiavistello con perno  
prismatico, Lucchetto  
a molla



LRR-53  
Chiavistello con  
bloccaggio, Lucchetto  
a molla acciaio



LRR-53  
Chiavistello con  
bloccaggio, Lucchetto  
a molla inox



SER69K  
Chiusura 1/4 di giro  
per agroalimentare,  
Inox