

 


 
 

- Slam latches for direct closing in hostile environments
- Latch tongue at top
- Resistant to water and cleaning products
- Materials:
Body and support: 304L stainless steel
Latch and handle: 303 stainless steel
Spring: 301 stainless steel

Advantages

- Openings on the top and mounting face allow easy cleaning (no retention of water or dirt)
- No sharp angles (avoids risk of injury)
- Top mounted handle allows easy opening

Applications

- Equipment for the food industry
- Animal breeding (hutches, hen-houses)
- Lids for metal enclosures used in humid environments
- Stainless steel strike plate not supplied

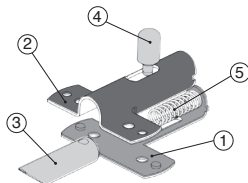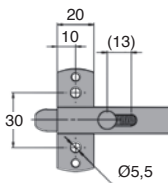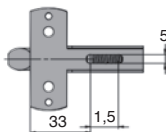

A version



B version

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-3%	-5%	-10%	On request

Part number	Latch stroke (mm)	Type	Stock*	Price each 1 to 49
LRR-56-A/SS	12	A version	✓	29,08 €
LRR-56-B/SS	13	B version	✓	29,08 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

Altri prodotti...



Tenditore, Inox



Ingranaggio dritto di precisione, Acciaio 20NCD2 cementato temprato



Articulated foot whit sheet metal base Ø40, Ø 40



Box kit di spine cilindriche DIN6325, Box kit - standard DIN 6325



Piastrina di riscontro, 15mm



Pressa manuale da banco, Pressione fino a 200kg



Coppia ruota e vite senza fine, Acciaio temprato




Grano punta in ottone, punta in ottone



Martinetto a vite - Vite rotante, Con



Ingranaggio interno, Acciaio 20NCD2

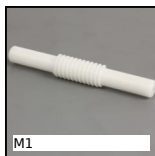

Coppia ruota e vite senza fine, Plastica



Perno folle, Standard - acciaio

Prodotti correlati



Chiavistello con perno prismatico, Lucchetto a molla



Chiavistello con bloccaggio, Lucchetto a molla acciaio



Chiavistello con bloccaggio, Lucchetto a molla inox



Small dimension system latch with locking system, Aluminium