


- Type C Carabiner
- White zinc plated steel
- Product carries no certification marking

Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

Info

- Not suitable for climbing
- Also exists in stainless steel

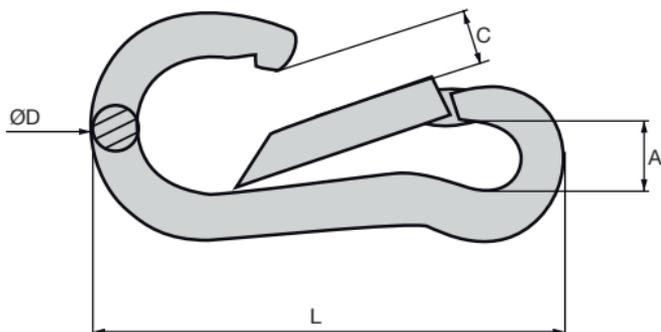

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc. List	-5%	-10%	-15%	-20%	On request	

Part number	ØD	L	A	C	SWL (kg)	Weight (g)	Price each 1 to 19
MAC5-50	5	50	8	7	50	16	1,37 €
MAC6-60	6	60	8	8	90	26	1,56 €
MAC7-70	7	70	11	9	150	44	2,11 €
MAC8-80	8	80	12	10	190	62	2,14 €
MAC9-90	9	90	13	11	230	92	2,35 €
MAC10-100	10	100	16	13	310	126	2,84 €
MAC11-120	11	120	19	17	340	192	3,54 €
MAC12-140	12	140	20	19	380	256	4,80 €

Altri prodotti...



PF30NM

Riduttore a ruota e vite senza fine, fino a 8.8 Nm



PTAF100-PAMF100

Piede fissabile con base lamiera Ø100, Ø 100



SEH

Attrezzo di bloccaggio a tirante, A tirante - inox



CM

Attrezzi Hygienic Usit® and Hygienic Design®, Combination spanner



GAC

Chiusura a leva con serratura, Riscontro grezzo



M1

Vite senza fine, Acciaio temprato



MSP3815

Inserto con piastrina a incollare Masterplate®, rettangolare con pe...



GARBAB

Perno di bloccaggio rapido manuale, A sfere



SLBS

Pistoncino a molla, Tutto inox



HTD5M_15

Puleggia dentata di trasmissione tipo



BAG-MI

Anello di serraggio con intaglio e



INS_SS

Inserto auto-filettante, Inox 316

Prodotti correlati



MACss

Moschettone inox, Inox