


- Type C Carabiner
- White zinc plated steel
- Product carries no certification marking

### Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

### Info

- Not suitable for climbing
- Also exists in stainless steel

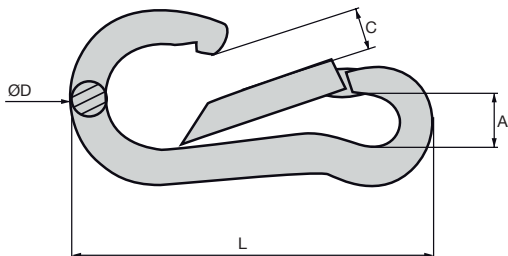

### DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc. List	-5%	-10%	-15%	-20%	On request	

Part number	ØD	L	A	C	SWL (kg)	Weight (g)	Price each 1 to 19
MAC5-50	5	50	8	7	50	16	1,37 €
MAC6-60	6	60	8	8	90	26	1,56 €
MAC7-70	7	70	11	9	150	44	2,11 €
MAC8-80	8	80	12	10	190	62	2,14 €
MAC9-90	9	90	13	11	230	92	2,35 €
MAC10-100	10	100	16	13	310	126	2,84 €
MAC11-120	11	120	19	17	340	192	3,54 €
MAC12-140	12	140	20	19	380	256	4,80 €

## Altri prodotti...



ESCON

Accessori per variatore di velocità 5A, Cavo USB per connessione PC



SH0

Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2



GPB

Impugnatura sferica, Con inserto ottone



METC

Cuscinetto a collare, Bronzo autolubrificante



BTE

Tenditore automatico universale, Per applicazioni correnti



PMC150\_M16

Supporto antivibrante a campana, Piastra a base quadrata



DTR

Pignone tendicatena, Ruota dentata in acciaio




CTZY

Antivibrante elastico sgolato, Acciaio



PR125

Piede fissabile con snodo - poliammide, Ø 123

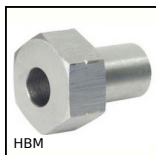

HBM

Guida su semi-binari, Boccola di regolazione



LVT

Mini martinetto motorizzato 1A, 1 ampere



BLHB30

Rinvio angolare ad albero cavo, Fino a 4.4 Nm

## Prodotti correlati



MACss

Moschettone inox, Inox