

Metal diameter 5 to 12mm

MACss


- **Type C Carabiner**
- Stainless steel 316
- Product carries no certification marking

Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

Info

- Not suitable for climbing
- Also exists in steel

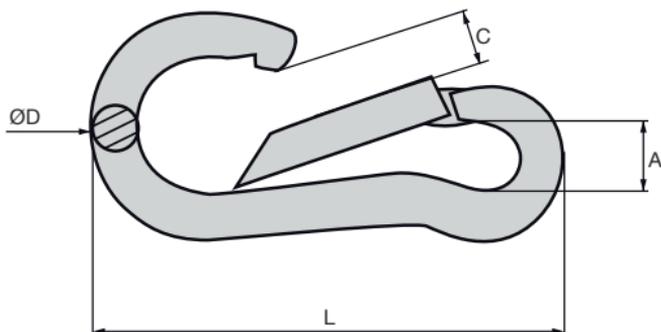

DISCOUNTS


Qty	1+	20+	40+	60+	80+	100+
Disc. List	-5%	-10%	-15%	-20%	On request	

Part number	D	L	A	C	SWL (kg)	Weight (g)	Price each 1 to 19
MAC5-50/SS	5	50	8	7	90	16	3,48 €
MAC6-60/SS	6	60	8	8	150	28	4,16 €
MAC7-70/SS	7	70	10	9	180	43	5,84 €
MAC8-80/SS	8	80	12	11	225	66	6,64 €
MAC10-100/SS	10	100	14	14	375	129	9,45 €
MAC11-120/SS	11	120	19	17	390	186	12,42 €
MAC12-140/SS	12	140	23	21	410	260	17,13 €

Altri prodotti...



ABL100005
Spazzola antistatica,
Standard

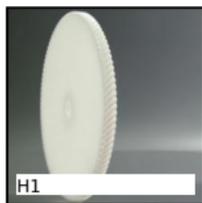

H1
Ingranaggio elicoidale
ad assi incrociati a
90°, Plastica lavorata



ACLEFS
Elementi di
ancoraggio, Standard



AKN
Giunto a soffietto
Gerwah®, da 22 a
180Nm




HG5
Ingranaggio dritto
acciaio, Acciaio
20NCD2



RBNpl
Ruota fissa con
piastra, Acciaio -
caucciù



PFM
Piede senza snodo,
Lamiera modellata

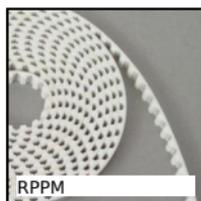

RPPM
Cinghia aperta al
metro tipo RPP, RPP5
Poliuretano armatura
in acciaio



CMM
Testa a snodo
maschio DIN



ALIDR30
Alimentazione, 1,5 A
and 2 A



RLR
Tenditore per catene
Roll-Ring®, Roll-



SFE
Testa a snodo
femmina, Inox / PTFE

Prodotti correlati



PPC55
Piastrina con anello,
Inox