


- Type C Carabiner
- Stainless steel 316
- Product carries no certification marking

### Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

### Info

- Not suitable for climbing
- Also exists in steel

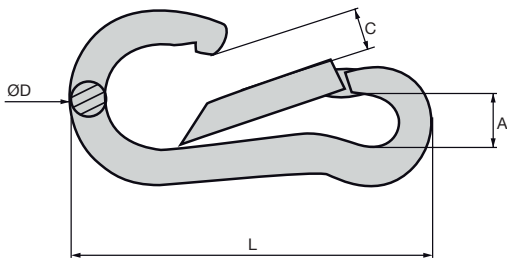

### DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc. List	-5%	-10%	-15%	-20%	On request	

Part number	D	L	A	C	SWL (kg)	Weight (g)	Price each 1 to 19
MAC5-50/SS	5	50	8	7	90	16	3,48 €
MAC6-60/SS	6	60	8	8	150	28	4,16 €
MAC7-70/SS	7	70	10	9	180	43	5,84 €
MAC8-80/SS	8	80	12	11	225	66	6,64 €
MAC10-100/SS	10	100	14	14	375	129	9,45 €
MAC11-120/SS	11	120	19	17	390	186	12,42 €
MAC12-140/SS	12	140	23	21	410	260	17,13 €

## Altri prodotti...



ZBconique  
Ingranaggio conico in  
plastica, 1:1



FB\_ECO  
Ingranaggio conico -  
Acciaio C43 - ECO, 4:1



GCL  
Guida lineare a sfere  
Eco, economica



TB\_ECO  
Ingranaggio conico -  
Acciaio C43 - ECO, 3:1



RFK38B  
Riduttore ipoide inox,  
fino a 200 Nm



BAP  
Anello di bloccaggio,  
Ø10 - Ø20



M0  
Coppia ruota e vite  
senza fine , Acciaio  
temprato



BOX-TOR-ORFS  
Valigetta di  
guarnizioni toriche in  
nitrile, 7.65 x 1.78mm  
a 37.82 x...



MDR\_SS  
Grillo con chiodo ad  
occhiello, Inox



HTD3M\_09  
Puleggia dentata di  
trasmissione tipo



ZBconique  
Ingranaggio conico in  
plastica, 1:1



CRM  
Cremagliera in nylon  
stampato, Nylon

## Prodotti correlati



PPC\_Ss  
Piastrina con anello,  
Inox