


- Type C Carabiner
- Stainless steel 316
- Product carries no certification marking

Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

Info

- Not suitable for climbing
- Also exists in steel

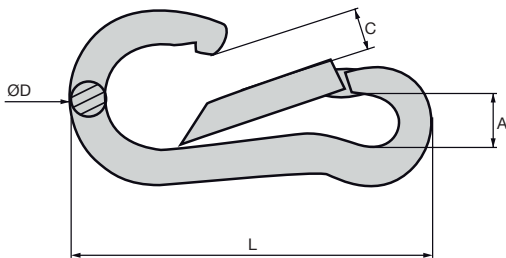

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc. List	-5%	-10%	-15%	-20%	On request	


Part number	D	L	A	C	SWL (kg)	Weight (g)	Price each 1 to 19
MAC5-50/SS	5	50	8	7	90	16	3,48 €
MAC6-60/SS	6	60	8	8	150	28	4,16 €
MAC7-70/SS	7	70	10	9	180	43	5,84 €
MAC8-80/SS	8	80	12	11	225	66	6,64 €
MAC10-100/SS	10	100	14	14	375	129	9,45 €
MAC11-120/SS	11	120	19	17	390	186	12,42 €
MAC12-140/SS	12	140	23	21	410	260	17,13 €

Altri prodotti...



WING

Dado ad alette per serraggio manuale, Inox DIN 314/315

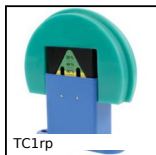

TC1rp

Tenditore per catena automatico, Con pattino 180°



SCE_SS

Serracavo, Inox



PITAss

Pistoncino a molla, con maniglia a T



SHA_PTR

Volantino pieno, Poliammide



PCS_PA6

, 9.525mm (DIN 06B-1)



RPP

Piastra di giunzione per cinghia RPP, RPP5



PRF4590_E

Squadra di giunzione, PRF4590



BLM

Pressore liscio a molla, Corpo termoplastica



INStool

Boccola autoflettante - Attrezzo, Strumento di posa



PFM

Piede senza snodo, Lamiera modellata



TBE12

Economic mini-table with trapezoidal leadscrew, 2kg

Prodotti correlati



PPCss

Piastrina con anello, Inox