


- Type C Carabiner
- Stainless steel 316
- Product carries no certification marking

### Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

### Info

- Not suitable for climbing
- Also exists in steel

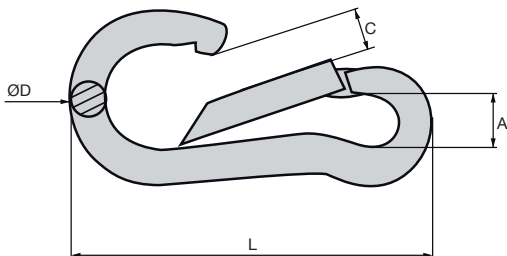

### DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc. List	-5%	-10%	-15%	-20%	On request	

Part number	D	L	A	C	SWL (kg)	Weight (g)	Price each 1 to 19
MAC5-50/SS	5	50	8	7	90	16	3,48 €
MAC6-60/SS	6	60	8	8	150	28	4,16 €
MAC7-70/SS	7	70	10	9	180	43	5,84 €
MAC8-80/SS	8	80	12	11	225	66	6,64 €
MAC10-100/SS	10	100	14	14	375	129	9,45 €
MAC11-120/SS	11	120	19	17	390	186	12,42 €
MAC12-140/SS	12	140	23	21	410	260	17,13 €

## Altri prodotti...



RURt

Ruota girevole a foro centrale, Poliuretano - Mozzo alluminio (Ultra...



PSG08

Ingranaggio dritto di precisione, Acciaio 20NCD2 cementato temprato



PV1R

Braccio portaventosa orientabile, Serraggio standard



UTKpwcr

Guida lineare Utilitrack®, Carello a rotelle - rivestimento polimero



PSG35

Ingranaggio dritto di precisione, Inox 303



RPCplss

Ruota girevole a doppio bloccaggio, Inox - poliammide



LVT

Mini martinetto motorizzato 4A, 4 ampere




NT61

Riduttore coassiale a treni paralleli, da 5 a 14 Nm - a treni parall...



PSP

Accessori per pannello, Profilo supporto per pannelli

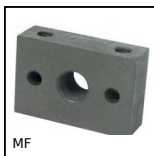

MF

Deceleratore, Flangia rettangolare



PTA80ssEB

Piede snodato con base stampata Ø80, Piede snodato



PRF-SCREEN-5

Screen support, Support with 5 axes of rotation

## Prodotti correlati



PPC55

Piastrina con anello, Inox