


# Motor gearbox, 12 or 24 Vdc New Size XS ★★★

## MAX22 Torque from 0.07 to 0.2 Nm


- Type of gearbox: spur gear
- Bearings: self lubricating bushes
- Avg angular backlash: 2° to 3°
- Max axial load: 15N
- Max radial load at 5 mm from fixing surface: 35 N
- Working temperature: -5 to 65 °C
- Weight: 104g min

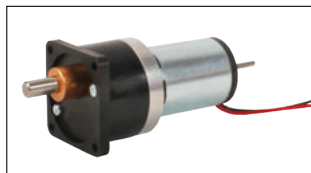

### Accessories

- ESCON-4Q-50/5 (servo-amplifier)
- NANODC-1Q-30/3 (speed controller)
- Power supplies: ALIDR30-12 and ALIDR30-24

Replaces the MAX30

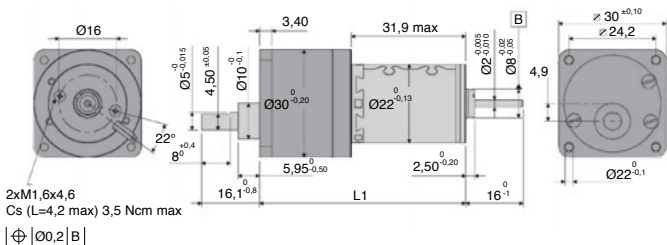

Wire length: 150 mm ±5  
Stripped and tinned ends: 4 mm ±1

### DISCOUNTS

Qty	1+	6+	10+
Disc. List	-7%	On request	

Part number	Ratio	N° of stages	Efficiency	L1 (mm)	No-load speed (rpm)	Speed under load (rpm)	Nominal torque (Nm)	Nominal current (CA)	Price each 1 to 5
<b>12 V version</b>									
MAX22-12-015	15:1	3	73%	54,9	356	176	0,07	0,30	158,62 €
MAX22-12-100	100:1	4	66%	57,4	53	47	0,10	0,08	183,34 €
MAX22-12-200	200:1	5	59%	62,4	27	23	0,20	0,09	189,52 €
<b>24 V version</b>									
MAX22-24-015	15:1	3	73%	54,9	435	252	0,07	0,18	158,62 €
MAX22-24-100	100:1	4	66%	57,4	65	58	0,10	0,05	161,83 €
MAX22-24-200	200:1	5	59%	62,4	33	29	0,20	0,05	189,52 €

Dimensions in mm

## Altri prodotti...



ZBconique

Ingranaggio conico in  
plastica, 1:1



AF

Giunto rigido con cava  
chiavetta, Set screw



G-ECO

Ingranaggio dritto  
acciaio - serie ECO,  
Acciaio C45



HK

Accessorio di  
serraggio manuale,  
Serraggio manuale  
LWL




BABss

Perno autobloccante  
inox 303, Inox 303



HCA

Grano magnetico con  
esagono incassato,  
Acciaio

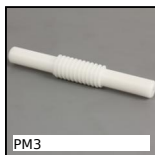

PM3

Coppia ruota e vite  
senza fine, Plastica  
lavorata (delrin)




ACLERP

Rulliera, Senza guida  
laterale



SLV

Attrezzo di bloccaggio  
a leva verticale, A  
leva verticale - acciaio

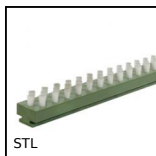

STL

Guida con spazzola,  
Spazzola



NT61

Riduttore coassiale a  
treni paralleli, da 5 a  
14 Nm - a treni



PM2

Coppia ruota e vite  
senza fine, Acciaio  
non temprato

## Prodotti correlati



ESCON

Variatore di velocità  
5A, 5 A



NANO

Variatore di velocità  
3A, 3 A



ALIDR30

Alimentazione, 1,5 A  
and 2 A