


Motor gearbox, 12 or 24 Vdc New Size XS ★★★

MAX22

Torque from 0.07 to 0.2 Nm


- Type of gearbox: spur gear
- Bearings: self lubricating bushes
- Avg angular backlash: 2° to 3°
- Max axial load: 15N
- Max radial load at 5 mm from fixing surface: 35 N
- Working temperature: -5 to 65 °C
- Weight: 104g min

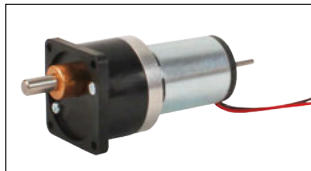

Accessories

- ESCON-4Q-50/5 (servo-amplifier)
- NANODC-1Q-30/3 (speed controller)
- Power supplies: ALIDR30-12 and ALIDR30-24

Replaces the MAX30

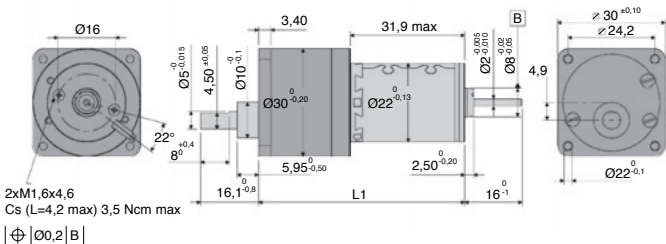

Wire length: 150 mm ±5
Stripped and tinned ends: 4 mm ±1

DISCOUNTS

Qty	1+	6+	10+
Disc. List	-7%	On request	

Part number	Ratio	N° of stages	Efficiency	L1 (mm)	No-load speed (rpm)	Speed under load (rpm)	Nominal torque (Nm)	Nominal current (CA)	Price each 1 to 5
12 V version									
MAX22-12-015	15:1	3	73%	54,9	356	176	0,07	0,30	158,62 €
MAX22-12-100	100:1	4	66%	57,4	53	47	0,10	0,08	183,34 €
MAX22-12-200	200:1	5	59%	62,4	27	23	0,20	0,09	189,52 €
24 V version									
MAX22-24-015	15:1	3	73%	54,9	435	252	0,07	0,18	158,62 €
MAX22-24-100	100:1	4	66%	57,4	65	58	0,10	0,05	161,83 €
MAX22-24-200	200:1	5	59%	62,4	33	29	0,20	0,05	189,52 €

Dimensions in mm

Altri prodotti...



CF
Perno folle, Standard -
acciaio



FF20
Riduttore ad alberi
paralleli, da 5.80 a 23
Nm



HBM
Guida su semi-binari,
Boccola di regolazione



BAGSS
Anello di bloccaggio
inox, Inox



BTE
Tenditore automatico
universale, Per
applicazioni correnti




CHAGC-AL
Cerniera ad avvitare,
Sfilabile



BLH40
Rinvio angolare a L,
da 3 a 10.30 Nm



OPFL_OPPM
Accessorio per
indicatori, Flangia
blocco albero

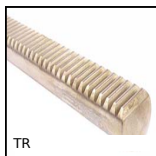

TR
Cremagliera sezione
circolare, Inox -



LPCM
Leva con impugnatura
cilindrica, Duroplast



EMR
Volantino zigrinato a
serraggio rapido,



PITAss
Pistoncino a molla,
con maniglia a T

Prodotti correlati



ESCON
Variatore di velocità
5A, 5 A



NANO
Variatore di velocità
3A, 3 A



ALIDR30
Alimentazione, 1,5 A
and 2 A