

New

Hexagonal ended handle

For use with manually operated bevel gearbox




MBEX

- Handle for operating RAM and RVM manual bevel gearboxes

- Material

Shaft: stainless steel

Rotating handle: plastic

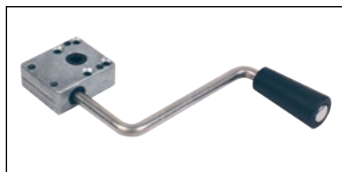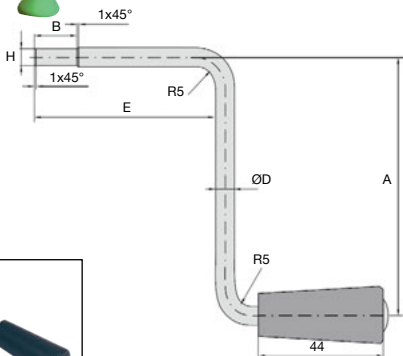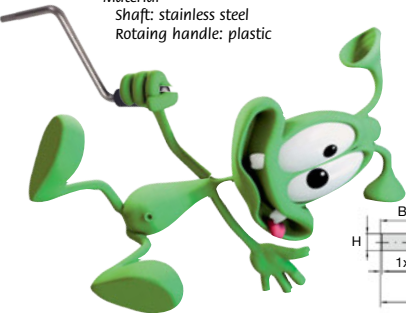

Used with a RVM14 gearbox

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	A	H	ØD	E	B	Price each
						1 to 9
MBEX6-90	90	hex 6mm	7	60	20	56,65 €
MBEX7-90	90	hex 7mm	8	62	15	45,32 €

Dimensions in mm

Altri prodotti...




ACLERP

Rulliera, Con guida laterale



ZG0

Ingranaggio dritto in plastica, Plastica lavorata (delrin)

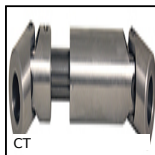

CT

Giunto cardanico telescopico, Sollecitazioni normale




T5P_T10P

Piastra di giunzione per cinghia T, T10



PRF-SCREEN-4

Screen support, Support with 4 axes of rotation

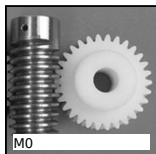


M0

Coppia ruota e vite senza fine , Plastica lavorata (delrin)




SSG1

Ingranaggio dritto Inox, Inox 304L

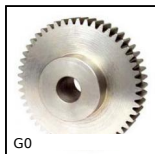

G0

Ingranaggio dritto acciaio, Acciaio 20NCD2

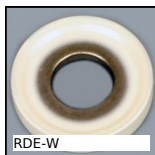

RDE-W

Rondella di tenuta Hygienic Usit®, Inox -



PRS80

Piede snodato tutto inox Ø80, Ø 80



TCC

Tenditore, Acciaio



BLHT20

Rinvio angolare a T, da 0.66 a 1.77 Nm

Prodotti correlati



RAM30

Riduttore manuale, Rinvio angolare



RVM14

Riduttore manuale, A ruota e vite senza fine



RAM35

Riduttore manuale, Rinvio angolare



RVM25

Riduttore manuale, Rinvio angolare