


Cylindrical reducing sleeve

SteSta

MCL

Steel or **stainless steel**

- **Male/female sleeve**
- Allows 2 rods of different diameters to be joined
- **Materials:**
 - Galvanised steel
 - 303 Stainless steel
- **Supplied by the pack**

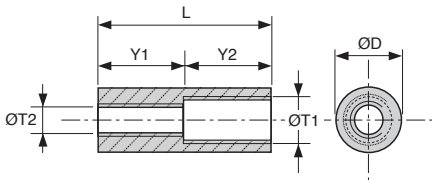

DISCOUNTS

Qty	1+	5+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	ØT1	ØT2	ØD	L	Y1	Y2	Qty per pack	Price each 1 to 4
Steel								
MCL6-8-40/B	M6	M8	13	40	20	20	20	19,82 €
MCL6-10-40/B	M6	M10	16	40	20	20	20	28,36 €
MCL8-10-40/B	M8	M10	16	40	20	20	20	28,36 €
MCL8-12-40/B	M8	M12	16	40	20	20	20	28,36 €
MCL10-12-40/B	M10	M12	16	40	20	20	20	28,36 €
MCL10-16-40/B	M10	M16	22	40	20	20	20	40,53 €
MCL12-16-40/B	M12	M16	22	40	20	20	20	40,53 €
Stainless steel								
MCL6-8-40/SS/B	M6	M8	13	40	20	20	20	53,60 €
MCL6-10-40/SS/B	M6	M10	16	40	20	20	20	70,75 €
MCL8-10-40/SS/B	M8	M10	16	40	20	20	20	70,75 €
MCL8-12-40/SS/B	M8	M12	16	40	20	20	20	70,75 €
MCL10-12-40/SS/B	M10	M12	16	40	20	20	20	70,75 €
MCL10-16-40/SS/B	M10	M16	22	40	20	20	20	130,85 €
MCL12-16-40/SS/B	M12	M16	22	40	20	20	20	130,85 €

Dimensions in mm

Altri prodotti...



UCFL_SS
Cuscinetto a flangia
ovale tutto inox, Inox



SMLS
Tavola lineare, Per
lunghezze ridotte



MPE
Distanziatore
esagonale, Acciaio



ACA
Albero scanalato in
acciaio, Acciaio



HTD3M_09
Puleggia dentata di
trasmissione tipo
HTD, HTD3 Alluminio



GE32
Chiusura a leva rigida
ad anello, Standard



MCLred
Manicotto di
riduzione, Cilindrico -
inox



GG2
Ingranaggio dritto
rettificato, Acciaio
trattato



NSR
Connettore rinvio
d'angolo, Regolabile



TPEf
Ruota per profili
alluminio, Fissa



ACLBTS
Sistema di chiusura,
Blocca porta a sfera



PPF
Pistoncino a molla,
con flangia

Prodotti correlati



MHXred
Manicotto di
riduzione, Esagonale -
inox



TIF
Asta filettata -
DIN975, Inox A2



TIFss
Tirante tutto filetto -
DIN976A, Inox



MCL
Manicotto cilindrico
maschiato, Cilindrico -
inox