

- For linking or closing chains
- Stainless steel 316
- Low cost range, no SWL specified

Application


- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

Info

- Also available in steel



NEW!

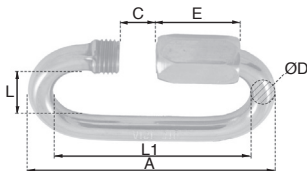

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	L1	L	C	E	Nominal load (kg)	Weight (g)	Price each 1 to 19
MRA1-03/SS/ECO	3,5	37,2	30,4	9,7	5,5	12,6	220	8	3,09 €
MRA1-04/SS/ECO	4,0	41,0	33,0	11,7	6,3	12,7	280	12	3,36 €
MRA1-05/SS/ECO	5,0	51,2	41,0	13,0	7,0	17,0	450	22	3,79 €
MRA1-06/SS/ECO	6,0	59,0	47,0	14,7	8,8	20,0	650	36	4,31 €
MRA1-07/SS/ECO	7,0	67,7	54,0	18,3	9,7	23,7	900	54	7,34 €
MRA1-08/SS/ECO	8,0	74,6	59,0	18,3	9,9	25,0	1100	76	8,59 €
MRA1-10/SS/ECO	10,0	89,0	70,0	22,2	12,8	30,0	1800	138	14,84 €
MRA1-12/SS/ECO	12,0	105,0	82,0	24,8	14,2	34,0	3500	224	23,71 €

Altri prodotti...



DEP

Attrezzi Hygienic Usit® and Hygienic Design®, Inserto di protezione...



AC156-157

Riscontro per chiusura a leva rigida ad anello, 25.5mm



PP35

Riduttore a ruota e vite senza fine, da 2.20 a 4.10 Nm



RBNpl

Ruota fissa con piastra, Acciaio - caucciù



ACLEPP

Angolare, 8 fori



TPEpbd

Ruota per profili alluminio, Girevole con freno



CHAsb89

Cerniera senza perno, □Cerniera in polimero




F7-SN

Visualizzatore multifunzione, Supporto snodato




ZDB

Ingranaggio conico in plastica, 2:1

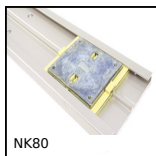


NK80

Guida mini Drylin® N, Larghezza 80mm

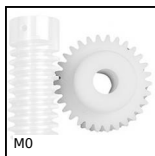

M0

Coppia ruota e vite senza fine, Plastica

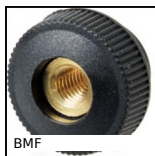

BMF

Manopola, Zigrinata - Passante

Prodotti correlati



CHN_CHNSS

Catena dritta a maglie lunghe, Inox



MRA_SS

Maglia rapida, Inox



MRAeco

Maglia rapida economica, Acciaio



MRA

Maglia rapida, Acciaio