

- For linking or closing chains
- Stainless steel 316
- Low cost range, no SWL specified

Application


- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

Info

- Also available in steel



NEW!

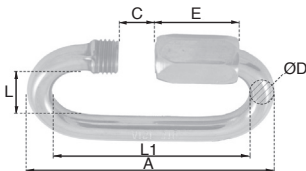


DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	L1	L	C	E	Nominal load (kg)	Weight (g)	Price each 1 to 19
MRA1-03/SS/ECO	3,5	37,2	30,4	9,7	5,5	12,6	220	8	3,09 €
MRA1-04/SS/ECO	4,0	41,0	33,0	11,7	6,3	12,7	280	12	3,36 €
MRA1-05/SS/ECO	5,0	51,2	41,0	13,0	7,0	17,0	450	22	3,79 €
MRA1-06/SS/ECO	6,0	59,0	47,0	14,7	8,8	20,0	650	36	4,31 €
MRA1-07/SS/ECO	7,0	67,7	54,0	18,3	9,7	23,7	900	54	7,34 €
MRA1-08/SS/ECO	8,0	74,6	59,0	18,3	9,9	25,0	1100	76	8,59 €
MRA1-10/SS/ECO	10,0	89,0	70,0	22,2	12,8	30,0	1800	138	14,84 €
MRA1-12/SS/ECO	12,0	105,0	82,0	24,8	14,2	34,0	3500	224	23,71 €

Altri prodotti...

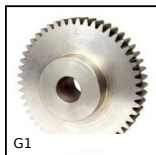

G1

Ingranaggio dritto
acciaio, Acciaio
20NCD2



BOX-TOR-C

Valigetta di
guarnizioni toriche in
nitrile, 3.00 x 1.50mm
a 30.20 x...



SVT15

Martinetto a vite - Vite
traslante, Vite
traslante



SRP

Spina cilindrica
ISO8752, elastica ISO
8752



CHC

Vite a testa cava
esagonale CHC,
Acciaio classe 12.19



UTKswc

Guida lineare
Utilitrack®, Ruota di
precisione a V in
acciaio



EX

Albero per riduttori E,
Albero doppio per
riduttori E




CNA-CNG

Staffa di montaggio
per molla a gas,
Staffa di montaggio a
squadra p...



F7-P-AM

Visualizzatore
multifunzione, Banda

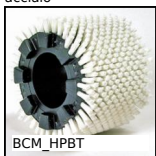


BCM_HPBT

Spazzola cilindrica
modulare, Filo



BLHT70

Rinvio angolare a T,
da 26 a 128 Nm

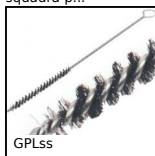

GPLss

Scovolo, inox

Prodotti correlati



CHN_CHNSS

Catena dritta a maglie
lunghe, Inox



MRA_SS

Maglia rapida, Inox



PPRss

Piastrina con anello,
Inox