

- For linking or closing chains
- Stainless steel 316
- Low cost range, no SWL specified

Application


- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

Info

- Also available in steel



NEW!

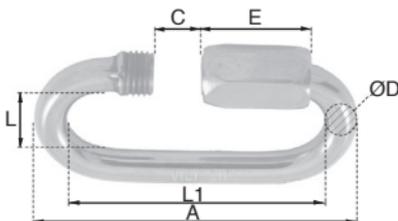

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	L1	L	C	E	Nominal load (kg)	Weight (g)	Price each 1 to 19
MRA1-03/SS/ECO	3,5	37,2	30,4	9,7	5,5	12,6	220	8	3,09 €
MRA1-04/SS/ECO	4,0	41,0	33,0	11,7	6,3	12,7	280	12	3,36 €
MRA1-05/SS/ECO	5,0	51,2	41,0	13,0	7,0	17,0	450	22	3,79 €
MRA1-06/SS/ECO	6,0	59,0	47,0	14,7	8,8	20,0	650	36	4,31 €
MRA1-07/SS/ECO	7,0	67,7	54,0	18,3	9,7	23,7	900	54	7,34 €
MRA1-08/SS/ECO	8,0	74,6	59,0	18,3	9,9	25,0	1100	76	8,59 €
MRA1-10/SS/ECO	10,0	89,0	70,0	22,2	12,8	30,0	1800	138	14,84 €
MRA1-12/SS/ECO	12,0	105,0	82,0	24,8	14,2	34,0	3500	224	23,71 €

Altri prodotti...



BFD

Perno ad innesto per
boccola, +180°C



VQTplqn

Chiusura ¼ di giro -
Piastra di bloccaggio,
Montaggio ad incastro




VDS

Bloccaggio scorrevole
per la regolazione,
Bloccaggio rapido per
foro...



PRF-SCREEN-5

Screen support,
Support with 5 axes of
rotation

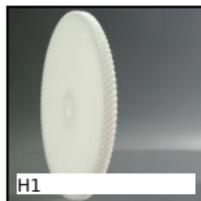

H1

Ingranaggio elicoidale
ad assi incrociati a
90°, Plastica lavorata



RFK38B

Riduttore ipoidale inox,
fino a 200 Nm



AT5P_AT10P

Piastra di giunzione
per cinghia AT, AT10



T10courroie

Cinghia di
posizionamento T,
T10 Poliuretano
armatura in acciaio



PF45

Riduttore a ruota e
vite senza fine, fino a
...



CAP815

Catena a tapparella
dritta, Stretta serie



AFSE

Perno di fissaggio, con
chiusura a scatto



AC

Piastrina di riscontro,
15mm

Prodotti correlati



CHN_CHNSS

Catena dritta a maglie
lunghe, Inox



MRA_SS

Maglia rapida, Inox



MRAeco

Maglia rapida
economica, Acciaio



MRA

Maglia rapida, Acciaio