


- For linking or closing chains
- White chromed steel
- Low cost range, no SWL specified
- Engraved with ring diameter

Application


- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

Info

- Also available in stainless steel

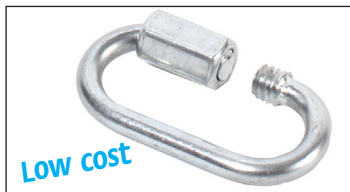

NEW!

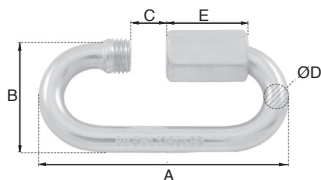

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	B	C	E	Nominal load (kg)	Weight (g)	Price each 1 to 19
MRA1-03/ECO	3,5	36	18	5,0	12	100	8	0,45 €
MRA1-04/ECO	4,0	41	20	6,0	14	180	12	0,55 €
MRA1-05/ECO	5,0	51	24	7,7	17	280	22	0,61 €
MRA1-06/ECO	6,0	59	27	8,5	21	400	36	0,73 €
MRA1-07/ECO	7,0	68	31	9,6	22	550	52	0,97 €
MRA1-08/ECO	8,0	74	34	10,4	24	700	76	1,13 €
MRA1-09/ECO	9,0	82	39	12,0	27	900	110	1,56 €
MRA1-10/ECO	10,0	90	42	13,5	30	1100	146	2,05 €
MRA1-12/ECO	12,0	106	48	14,8	34	1500	234	3,15 €
MRA1-14/ECO	14,0	122	56	15,5	40	2200	358	6,24 €
MRA1-16/ECO	16,0	141	63	17,5	44	2900	520	10,12 €

Altri prodotti...



LWL

Guida lineare a sfere -
Sfere inox, Carello -
da 514 N a 16700 N



RPCplss

Ruota girevole a
doppio bloccaggio,
Inox - poliammide



PRFRTR

Elementi di giunzione,
Giunto di
collegamento
trasversale



HAS

Rondella girevole, Vite
con spalla a testa
piatta con intaglio



CHAE6555

Cerniera ad avvitare
estetica, Alluminio



H0

Ingranaggio elicoidale
ad assi incrociati a
90°, Acciaio 20NCD2



GG3

Ingranaggio dritto
rettificato, Acciaio
trattato



GE1006

Chiusura a leva
adattabile, Per
aggancio in gola



MSP3815

Inserto con piastrina a
incollare
Masterplate®,



LVT

Mini martinetto
motorizzato 2A, 2
ampere



SCR

Accessori per ventosa,
Adattatore per inserto



LRR-53

Chiavistello con
bloccaggio, Lucchetto
a molla acciaio

Prodotti correlati



MRA

Maglia rapida, Acciaio



MRA_SS

Maglia rapida, Inox



MRASeco

Maglia rapida
economica, Inox



FCHN_CHNSS

Catena dritta a maglie
lunghe, Acciaio
zincato